



# U-Bent Rapid Start T12

FB40T12/6 SPEC35 ALTO

Philips T12 fluorescent lamps provide high performance and long life in a wide range of sizes, shapes, and types.

## Product data

### • General Characteristics

Base	Medium Bi-Pin [Medium Bi-Pin Fluorescent]
Base Information	Green Base
Bulb	T12-6U [U-bent T 12/8 inch with 6" spacing]
Rated Avg. Life [3 hr Start]	18000 hr
Energy Saving	Not Applicable

### • Light Technical Characteristics

Color Code	SPEC35 [CCT of 3500K]
Color Rendering Index	73 Ra8
Color Designation	SPEC35
Color Temperature	3500 K
Initial lumen	3050 Lm
Design Mean Lumens	2775 Lm

### • Electrical Characteristics

Watts	40 W
-------	------

### • Environmental Characteristics

Mercury (Hg) Content	4.4 mg
----------------------	--------

### • Product Dimensions

Nominal Length [inch]	22.44
-----------------------	-------

### • Product Data


Product number	378547
Full product name	FB40T12/6 SPEC35 ALTO
Short product name	FB40T12/6 SPEC35 ALTO
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677378547
Bar code on case	50046677378542
Logistics code(s)	927862073507
eop_net_weight_pp	0.001 kg

# PHILIPS


sense and simplicity

# U-Bent Rapid Start T12


## Dimensional drawing

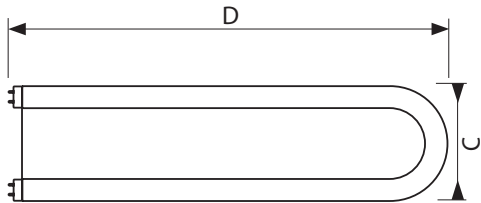

G13, T12-UR

 

G13

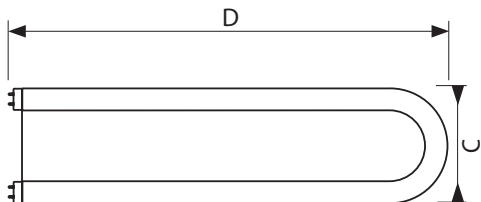

G13, T12-UR



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change