



# U-Bent Rapid Start T12

FB40T12/6 41U ALTO

Philips T12 fluorescent lamps provide high performance and long life in a wide range of sizes, shapes, and types.

## Product data

### • General Characteristics

|                              |   |
|------------------------------|---|
| Base                         | Medium Bi-Pin [Medium Bi-Pin Fluorescent]   |
| Base Information             | Green Base                                  |
| Bulb                         | T12-6U [U-bent T 12/8 inch with 6" spacing] |
| Rated Avg. Life [3 hr Start] | 18000 hr                                    |
| Energy Saving                | Not Applicable                              |

### • Light Technical Characteristics

|                       |                             |
|-----------------------|-----------------------------|
| Color Code            | Ultralume 41 [CCT of 4100K] |
| Color Rendering Index | 85 Ra8                      |
| Color Designation     | Ultralume 41                |
| Color Temperature     | 4100 K                      |
| Initial lumen         | 3100 Lm                     |
| Design Mean Lumens    | 2850 Lm                     |

### • Electrical Characteristics

|       |      |
|-------|------|
| Watts | 40 W |
|-------|------|

### • Product Dimensions

|                       |       |
|-----------------------|-------|
| Nominal Length [inch] | 22.44 |
|-----------------------|-------|

### • Product Data

|                    |                    |
|--------------------|--------------------|
| Product number     | 378760             |
| Full product name  | FB40T12/6 41U ALTO |
| Short product name | FB40T12/6 41U ALTO |
| Pieces per Sku     | 1                  |
| eop_pck_cfg        | 12                 |
| Skus/Case          | 12                 |
| Bar code on pack   | 46677378769        |
| Bar code on case   | 50046677378764     |
| Logistics code(s)  | 927862084106       |
| eop_net_weight_pp  | 0.001 kg           |

# PHILIPS

 
sense and simplicity

# U-Bent Rapid Start T12


Dimensional drawing



G13, T12-UR



G13

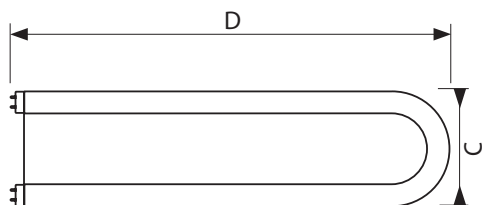

G13, T12-UR



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change