

Circline

22W Daylight Deluxe C-T9 1CT

T9 4-Pin Circular Fluorescent Lamps.



Product data

• General Characteristics

Base	G10q
Bulb	C-T9 [C-T 29 mm]

• Light Technical Characteristics

Color Code	54
Color Rendering Index	79 Ra8
Color Designation	Cool Daylight
Color Temperature	6200 K
Chromaticity Coordinate X	313 -
Chromaticity Coordinate Y	337 -
Initial Lumens	910 Lm
Lumen Maintenance 2000h	85 %
Lumen Maintenance 5000h	75 %

• Electrical Characteristics

Watts	22 W
-------	------

Lamp Wattage	20.5 W
Lamp Voltage	61 V
Lamp Current EM	0.37 A

• Product Dimensions


Diameter D	26.2 (min), 31.0 (max) mm
Overall Width E	203.2 (min), 215.9 (max) mm
Inner Width I	149.1 (min), 155.7 (max) mm

• Product Data

Product number	392357
Full product name	22W Daylight Deluxe C-T9 1CT
Short product name	FC8T9/DAYDLX/22W/8 12PK
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677392352
Bar code on case	50046677392357
Logistics code(s)	928028405435
eop_net_weight_pp	0.110 kg


Dimensional drawing

Dimensional drawing

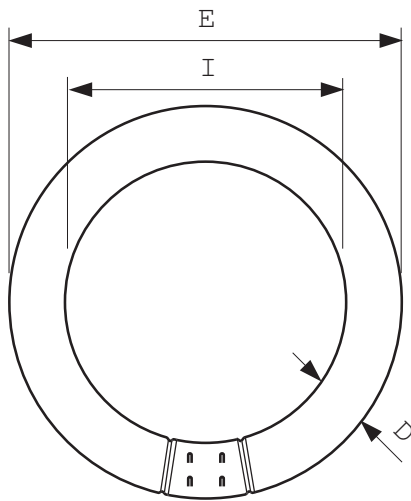

G10q, C-T9

Product	D (Min)	D (Max)	E (Min)	E (Max)	I (Min)	I (Max)
TL-E 22W/54 RS	26.2	31.0	203.2	215.9	149.1	155.7

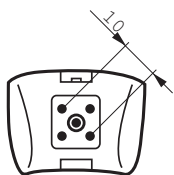

G10q



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change