

# Circline

## FC12T9/Daylight Deluxe

T9 4-Pin Circular Fluorescent Lamps.



### Product data

#### • General Characteristics

Base	G10q
Bulb	C-T9 [C-T 29 mm]

#### • Light Technical Characteristics

Color Code	54
Color Rendering Index	79 Ra8
Color Designation	Cool Daylight
Color Temperature	6200 K
Chromaticity Coordinate X	313 -
Chromaticity Coordinate Y	337 -
Initial Lumens	1570 Lm
Lumen Maintenance 2000h	85 %
Lumen Maintenance 5000h	75 %

#### • Electrical Characteristics

Watts	32 W
-------	------

Lamp Wattage	31 W
Lamp Voltage	84 V
Lamp Current EM	0.43 A

#### • Product Dimensions


Diameter D	26.2 (min), 31.0 (max) mm
Overall Width E	292.1 (min), 304.8 (max) mm
Inner Width I	239.5 (min), 246.1 (max) mm

#### • Product Data

Product number	262600
Full product name	FC12T9/Daylight Deluxe
Short product name	FC12T9/DAYLIGHT DELUXE 12PK
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677262600
Bar code on case	50046677262605
Logistics code(s)	928028605435
eop_net_weight_pp	0.180 kg


### Dimensional drawing

Dimensional drawing

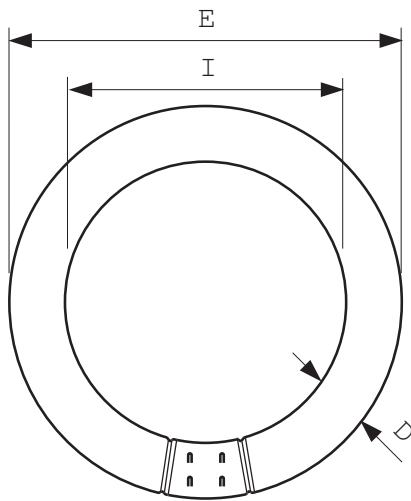

G10q, C-T9

Product	D (Min)	D (Max)	E (Min)	E (Max)	I (Min)	I (Max)
TL-E 32W/54 RS	26.2	31.0	292.1	304.8	239.5	246.1

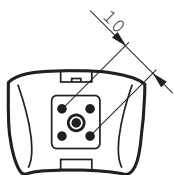

G10q



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change