



# Energy Saver Twisters

## Decorative Twister 42W Med EL/DT 1CT

Looking for an energy saver that does not look like one? The Philips EnergySaver family provides energy efficient lighting options that don't just provide similar light as your standard incandescent light bulb, they also have the same classic shapes. Try the Philips EnergySavers and see how they truly provide advanced lighting designed around your needs.

### Product data

#### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Bulb	EL/DT
RatedAvgLife(See Family Notes)	12000 hr
Rated Avg. Life [3 hr Start]	8000 hr
Energy Saving	Energy Saving
Estimated Energy Cost/YR	5.06 \$
Life with 3h/day use [years]	11 an

#### • Light Technical Characteristics

Color Rendering Index	82 Ra8
Color Temperature	2780 K
Initial lumen	2800 Lm

#### • Electrical Characteristics

Watts	42 W
-------	------

#### • Environmental Characteristics

Mercury (Hg) Content	5 mg
----------------------	------

#### • Product Dimensions

Max Overall Length (MOL) - C	7.08 (max) in
------------------------------	---------------

#### • Product Data

Product number	139485
Full product name	Decorative Twister 42W Med EL/DT 1CT
Short product name	MARTHON DEC TWIST EL/DT42W
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677139483
Bar code on case	50046677139488
Logistics code(s)	929689947702
eop_net_weight_pp	0.175 kg

### Dimensional drawing


# PHILIPS

sense and simplicity

## Dimensional drawing

### E26, EL/DT

Product	C (Max)	D (Norm)
Cl-Dt 42W E26 EL/DT ES	7,08	-

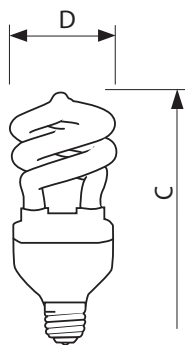

E26



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change