

Energy Saver Decoratives

5W Cand EL/A MCAN 1CT



Philips Energy Saver Decorative CFLs provide energy savings and reduce operating costs without sacrificing quality of light compared to incandescent equivalents.

Product data

• General Characteristics

Base	Candelabra [Candelabra Screw]
Bulb	EL/A MCAN
RatedAvgLife(See Family Notes)	6000 hr

• Light Technical Characteristics

Color Code	827 [CCT of 2700K]
Color Rendering Index	81 (min), 82 (nom) Ra8
Color Designation	Warm White
Color Temperature	2700 K
Chromaticity Coordinate X	463 -
Chromaticity Coordinate Y	420 -
Initial lumen	200 Lm
Luminous Efficacy	40 Lm/W
Lamp	
Lumen Maintenance 2000h	85 %
Lumen Maintenance 5000h	75 %

• Electrical Characteristics

Watts	5 W
Power Factor	0.55 -
Voltage	110-127 V

Lamp Current mA	75 mA
Line Frequency	50/60 Hz
Dimmable	No

• Environmental Characteristics

Energy Efficiency Label (EEL)	A
Mercury (Hg) Content	1.5 mg

• Product Dimensions


Overall Length C	117 (max) mm
Diameter D	42 (max) mm
Width F	41.4 (max) mm

• Product Data

Product number	147918
Full product name	5W Cand EL/A MCAN 1CT
Short product name	EL/MCAN 5W MART MINI CAN BASE
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677147914
Bar code on case	50046677147919
Logistics code(s)	929689982101
eop_net_weight_pp	0.060 kg


Dimensional drawing

Dimensional drawing

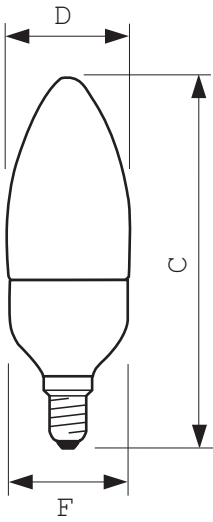

E12/E14, B35/B39/EL/A MCAN

Product	C (Max)	D (Max)	F (Max)
Candle 5W/827 E12 110-127V 50/60Hz	117	42	41.4

 

E12



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change