



Energy Saver Decoratives

23W EL/A G40 1CT

Philips Energy Saver Decorative CFLs provide energy savings and reduce operating costs without sacrificing quality of light compared to incandescent equivalents.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Bulb	EL/A G40
RatedAvgLife(See Family Notes)	10000 hr
Rated Avg. Life [3 hr Start]	8000 hr
Energy Saving	Energy Saving
Estimated Energy Cost/YR	2.77 \$
Life with 3h/day use [years]	9.1 an

• Light Technical Characteristics

Color Rendering Index	82 Ra8
Color Temperature	2700 K
Initial lumen	1400 Lm

• Electrical Characteristics

Watts	23 W
-------	------

• Environmental Characteristics

Mercury (Hg) Content	3.7 mg
----------------------	--------


• Product Data

Product number	211078
Full product name	23W EL/A G40 1CT
Short product name	EL/A G40 23W 120V 6/1
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677211073
Bar code on case	50046677211078
Logistics code(s)	929689983501
eop_net_weight_pp	0.185 kg


PHILIPS

sense and simplicity

Dimensional drawing

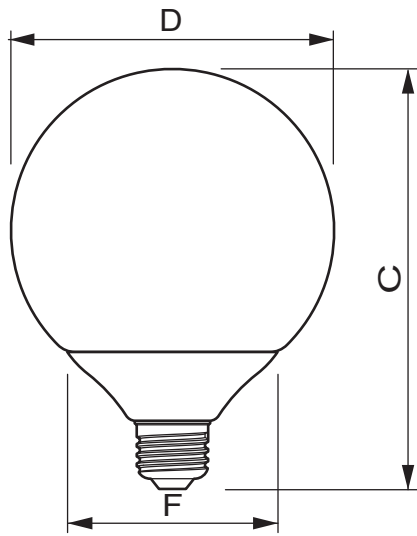

E26, G30/G40

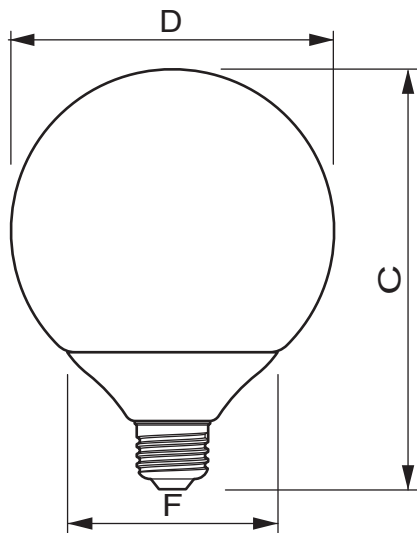

E26, G30/G40



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change