

# CorePro LED Lamps

10.5A19/COREPRO/3000 6/1

Philips CorePro LED Lamps provide an energy efficient lighting solution



**PHILIPS**

## Product data

### • General Characteristics

|                         |              |
|-------------------------|--------------|
| Cap-Base                | E26          |
| Bulb                    | A60 [A 60mm] |
| Rated Avg. Life (Hours) | 15000 hr     |
| Nominal Lifetime hours  | 15000 hr     |

### • Light Technical Characteristics

|                              |                    |
|------------------------------|--------------------|
| Color Code                   | WW                 |
| Color Designation            | White              |
| Correlated Color Temperature | 3000 K             |
| Approximate Lumens           | 800 Lm             |
| CRI                          | 80                 |
| Luminous Efficacy            | 76.19 Lm/W         |
| Lamp Color Temp. (Kelvin)    | 3000 K [CCT 3000K] |
| Rated Luminous Flux          | 800 Lm             |
| LLMF - end nominal lifetime  | 70 %               |
| Colour consistency           | 6 steps            |

### • Electrical Characteristics

|                    |          |
|--------------------|----------|
| Wattage            | 10.5 W   |
| Wattage Technical  | 10.5 W   |
| Voltage            | 120 V    |
| Line Frequency     | 50-60 Hz |
| Power Factor       | 0.7 -    |
| Lamp Current mA    | 103 mA   |
| Dimmable           | No       |
| Wattage Equivalent | 60 W     |
| Rated Wattage      | 10.5 W   |
| Starting Time      | 0.5 s    |

Suitable for accent lighting No

### • Temperature Characteristics

### • Environmental characteristics

Energy Efficiency Label (EEL) A

### • Measuring Conditions

Switching cycle 50000X

### • Product Dimensions

Overall Length C 99.3 mm  
Diameter D 59.3 mm

### • Product Data


|                             |                          |
|-----------------------------|--------------------------|
| Order code                  | 929000220404             |
| Full product code           | 929000220404             |
| Full product name           | 10.5A19/COREPRO/3000 6/1 |
| Order product name          | 10.5A19/COREPRO/3000 6/1 |
| Pieces per pack             | 1                        |
| Packing configuration       | 6                        |
| Packs per outerbox          | 6                        |
| Bar code on pack - EAN1     | 46677430511              |
| Bar code on outerbox - EAN3 | 50046677430516           |
| Logistic code(s) - 12NC     | 929000220404             |
| Net weight per piece        | 0.074 kg                 |

## Warnings and Safety

- Suitable for use in damp locations.

- Not for use in totally enclosed luminaires.
- Before replacing, turn off power and let lamp cool to avoid electrical shock or burn.

## Dimensional drawing

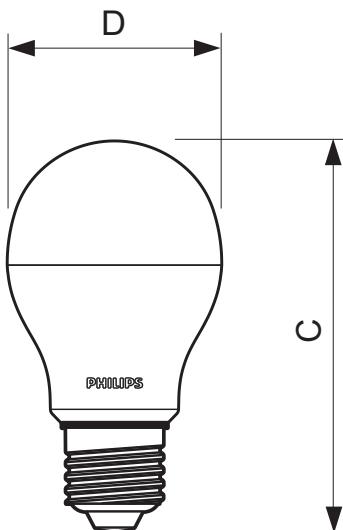

### 10.5A19/COREPRO/3000 6/1

| Product              | C (Norm) | C1 (Max) | D (Norm) | D1 (Norm) |
|----------------------|----------|----------|----------|-----------|
| LED 10.5-60W E26 830 | 99.3     | -        | 59.3     | -         |

## Dimensional drawing



E26



© 2014 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2014, May 31  
data subject to change