



Halogená Energy Advantage "GLS"

53A19/EV/NTL 120V 12/2

Philips Halogená® Energy Advantage Lamps use less energy while maintaining bright, crisp, white halogen light. Available in traditional lamp shapes to fit most incandescent fixtures. Halogená Energy Savers work with dimmer switches, and are available in the familiar "A" and decorative shapes. Use them in your existing fixtures and your home will look great while you save energy.

Product data

• General Information

Cap-Base	E26
Bulb Shape	A-19 (A19)
Operating Position	UNIVERSAL [Any or Universal (U)]
Main Application	General Lighting (G)
Gas Filling	Gas

• Light Technical

Luminous Flux (Nom)	830 lm
Color Rendering Index (Nom)	100

• Operating and Electrical

Power (Rated) (Nom)	53 W
Voltage (Nom)	120 V

• Mechanical and Housing


Bulb Finish	Daylight-Blue
Cap-Base Information	Aluminium Cap
Bulb Material	Soft Glass
Filament Shape	CC-8 [Axial]

• Product Data

Order product name	53A19/EV/NTL 120V 12/2
EAN/UPC - Product	50046677226966
Order code	925620820501
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	925620820501
Net Weight (Piece)	0.001 kg

PHILIPS

Dimensional drawing

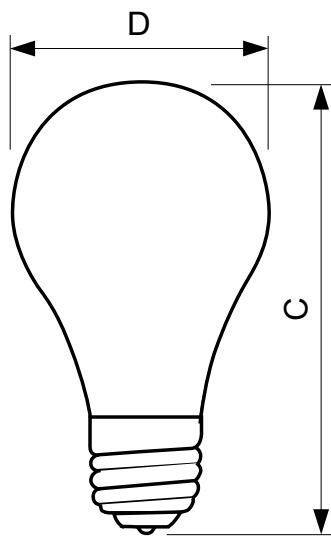

E26, A19

53W E26/ALC 120V A-19 D-B

Product

53A19/EV/NTL 120V 12/2



© 2015 Philips Lighting Holding B.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2015, November 29
data subject to change