



ROUGHLYTE™ Series

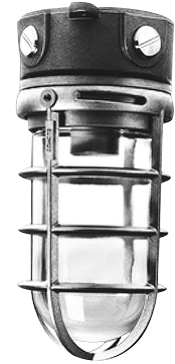

ORDERING INFORMATION

Catalog Number: Example: VCXL11GC

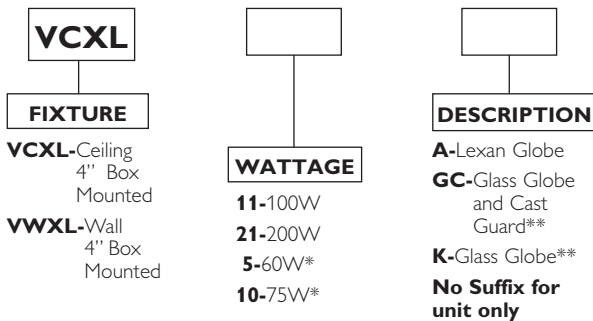

*60W and 75W available with lexan globe only. **For use with 100W and 200W units only.

PRODUCT SPECIFICATIONS

- VCXL Roughlyte fixtures are for use on ceilings and canopies. VWXL Roughlyte fixtures are for use on walls and columns. Roughlyte fixtures guard against moisture and debris in exterior applications (for globe down mounting only). **Not recommended for use in hazardous locations.**
- Complete with 4" die-cast aluminum box, four side and top hole tapped 1/2" NPT (four plugs included).
- Heat and shock resistant glass or polycarbonate globe.
- Cast aluminum bayonet guard with allen head security screws.
- Sockets are pre-wired with extra long 1/2" stripped leads.
- To use VCXL units with 3/4" conduit use VK Series with VXL13 universal box.
- To use VWXL units with 3/4" conduit, use VW Series with VXL13 universal box.
- Patented.

ACCESSORIES


Accessories - See page 5-A

TECHNICAL INFORMATION


All incandescent Roughlyte ceiling and wall fixtures are not supplied with a lamp. This fixture requires a medium base incandescent A lamp. The lamp can be clear or coated.

DIMENSIONS


Catalog No.	Height (H)	Dia. (D)
VCXL11	3-3/4"	4-1/4"
VCXL21	3-3/4"	5-1/8"
VCXL11K	8-5/8"	4-1/4"
VCXL21K	0-3/8"	5-1/8"
VCXL11GC	9-1/8"	4-1/4"
VCXL21GC	10-7/8"	5-1/4"
VCXL5A	8-5/8"	4-1/4"
VCXL10A	10-3/8"	5-1/8"
VWXL	12-3/4"	7"
VWXL11	4-1/4"	7-1/8"
VWXL21	4-1/4"	7-7/16"
VWXL11K	9-1/4"	7-1/8"
VWXL21K	10-7/8"	7-7/16"
VWXL11GC	9-3/4"	7-1/4"
VWXL21GC	11-3/8"	7-1/2"
VWXL5A	9-1/4"	7-1/8"
VWXL10A	10-7/8"	7-7/16"

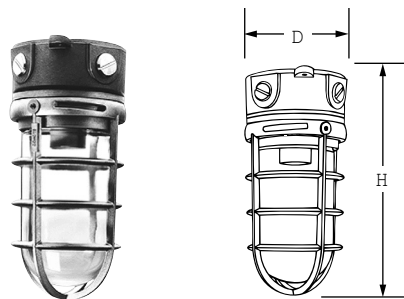

VCXL11GC

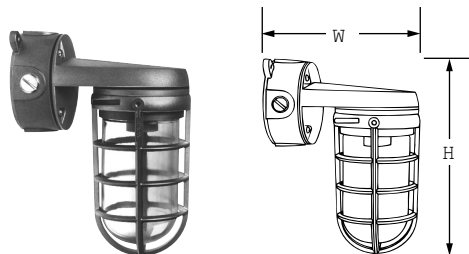

VWXL

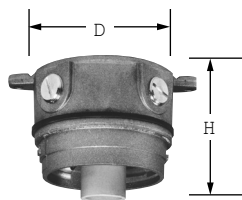

VCXL11
Box Mount
Adapter

Roughlyte is a registered trademark of Stonco and is not for use in hazardous areas.



UL Wet Location Listed.
UL File Number: E57163