


CATALOG NO. \_\_\_\_\_



TYPE NO. \_\_\_\_\_


JOB NAME \_\_\_\_\_

# ROUGHLYTE™ Series Pendant Mount

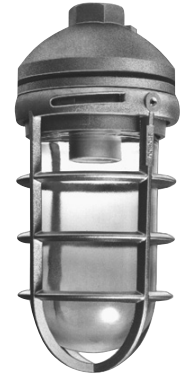

## ORDERING INFORMATION

Catalog Number: Example: VP11GC

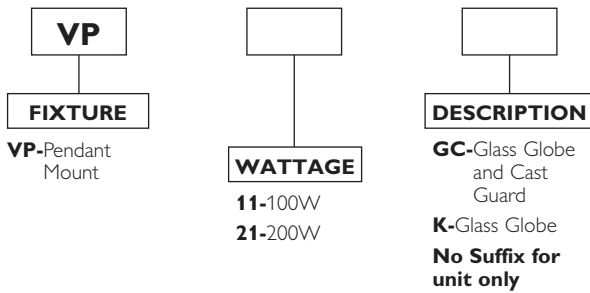

## PRODUCT SPECIFICATIONS

- VP Roughlyte fixtures are for use pendant applications, stems not included. VP guard against moisture and debris in exterior applications (for globe down mounting only). **Not recommended for use in hazardous locations.**
- Top hub tapped 1/2" NPT.
- Heat and shock resistant glass globe.
- Sockets are pre-wired with extra long 1/2" stripped leads.
- Patented.

## ACCESSORIES


Accessories - See page 5-A

## TECHNICAL INFORMATION


All incandescent Roughlyte ceiling and wall fixtures are not supplied with a lamp. This fixture requires a medium base incandescent A lamp. The lamp can be clear or coated.

### DIMENSIONS

Catalog No.	Height (H)	Dia. (D)
VP11	4"	4-1/8"
VP21	4"	5-1/8"
VP11K	9-1/4"	4-1/8"
VP21K	10-3/8"	5-1/8"
VP11GC	9-3/4"	4-5/16"
VP21GC	10-7/8"	5-5/16"

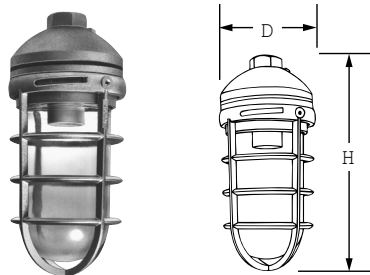

VP11GC  
Pendant Unit with  
Cast Guard and Glass Globe

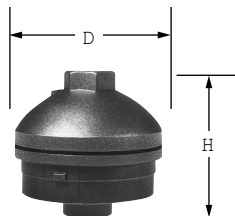

VP11  
Pendant Adapter



UL Wet Location Listed.  
UL File Number: E57163

Roughlyte is a registered trademark of Stonco and is not for use in hazardous areas.