


Cross Section

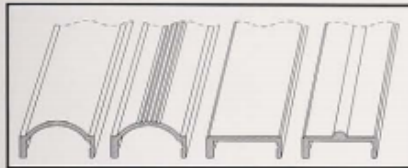

If desired an optional snap-on fascia completes the installation. Choose between an architecturally strong square, a simple oval, a ribbed shape or an oval with grooved shape.

Fascia may be field cut to fit any cabinet or shelf width. Mounting clips provided to ensure secure installation.

**ORDERING INFORMATION**

**Xenix™**  
**Cat. No.**                      **Description**                      **Fixture Dimensions**

**Light Modules**  
 XN12 ..... 12" module ..... 12"L x 2 1/2"W x 1"D

*Note: Order enough modules in 12" increments to fit your space.  
 Add suffix: -WH white or -AL aluminum. (Black end caps.)*

**Xenix Non-Modular Light**  
 XN24 ..... 24" non-modular ..... 24"L x 2 1/2"W x 1"D  
 XN36 ..... 36" non-modular ..... 36"L x 2 1/2"W x 1"D  
 XN48 ..... 48" non-modular ..... 48"L x 2 1/2"W x 1"D

**Xenix Power Feed**  
 XNDW\* ..... Direct wire feed ..... 2 3/4 x 1 1/4 x 1"  
 XNCS\* ..... Portable power feed w/ 6' cordset. 2 3/4 x 1 1/4 x 1"

*\*Add suffix: -WH white or -BLK black. Example: XNDW-WH.*


**Xenix Flush Connector & Interconnect Cords**  
 XNC ..... Xenon flush module connector  
 XNICF\* ..... 12"-36" Coiled Interconnect Cord  
 XNICS\* ..... 6" Straight Interconnect Cord

*\*Add suffix: -BLK black or -WH white. Example: XNICF-WH.  
 Note: Order one connector or interconnect cord for each module connection.*

**Xenix Factory or Field Installed Diffuser**  
 AXN12 ..... Opal white diffuser for XN12  
 AXN24 ..... Opal white diffuser for XN24  
 AXN36 ..... Opal white diffuser for XN36  
 AXN48 ..... Opal white diffuser for XN48

**Fascia Styles**  
 XN04 (4') or XN08 (8') ..... Oval ..... 4' or 8'  
 XNG4 (4') or XNG8 (8') ..... Grooved ..... 4' or 8'  
 XNS4 (4') or XNS8 (8') ..... Squared ..... 4' or 8'  
 XNR4 (4') or XNR8 (8') ..... Ribbed ..... 4' or 8'

*Note: Add suffix: -BLK black, -WH white, or -AL aluminum.  
 Use a quality line voltage incandescent dimmer.  
 Maximum of 5 modules from one electrical feed.  
 Power feed can be installed at either end of run. Adds 3" to installed length.  
 Frosted lens optional. UL does not require lenses for Xenon fixtures.  
 Lamps included.  
 Consult specification binder for details.*

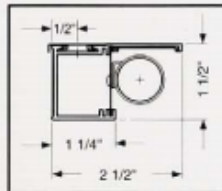

Cross Section

**ORDERING INFORMATION**

**Custom Length Incandescents**  
**Cat. No.**                      **Overall Fixture Length**

CLI2012 ..... 12" (minimum)  
 CLI2018 ..... 18" (or less - as specified)  
 CLI2024 ..... 24" (or less - as specified)  
 CLI2030 ..... 30" (or less - as specified)  
 CLI2036 ..... 36" (or less - as specified)  
 CLI2048 ..... 48" (or less - as specified)  
 CLI2060 ..... 60" (or less - as specified)  
 CLI2072 ..... 72" (or less - as specified)  
 CLI2084 ..... 84" (or less - as specified)  
 CLI2096 ..... 96" (or less - as specified)


**STANDARD FINISHES** (must add as suffix)

/BZ ..... Dark Bronze  
 /ES ..... Etched Silver  
 /PG ..... Polished Gold

*Note: Lamps included.  
 25 watt T6 1/2 frosted incandescent lamp. 1500 hr. lamp life.  
 Consult specification binder for details.*

**FIXTURE LENGTH AND LAMP COUNT**

Length	No. of Lamps
12" to <18"	1
18" to <26"	2
26" to <33"	3
33" to <40"	4
40" to <47"	5
47" to <54"	6
54" to <61"	7
61" to <68"	8
68" to <75"	9
75" to <82"	10
82" to <89"	11
89" to 96"	12

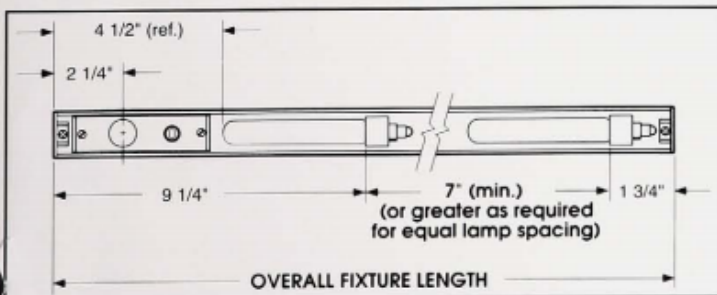

Cross Section

Fixtures containing 2 lamps have second lamp mounted in reverse orientation (base-to-base) than shown.