

Type No. _____

Catalog No. _____

Job. Name _____

GeoScapes Mini LED

Architectural LED Wall Sconce

APPLICATIONS

- Provides safety and security in residential and light commercial applications in locations such as entrances, over garages, illuminate house numbers and located along perimeters and pathways


CONSTRUCTION

- Housing constructed of heavy die cast aluminum and fully gasketed
- Corrosion resistant Duraplex II polyester powder coated finish available in white and titanium gray
- Acrylic lens
- Integral cast aluminum heat sink ensures cool operation
- Complete with integral splice chamber
- Patent pending design




OPTICS

- Seven high-output LEDs having an average rated life of 60,000 hours (at 70% lumen output)
- Patented Philips LED Optical System individually controls the placement of light in the target area
- 4100k neutral white color temperature
- Type III distribution with shielded optics and no uplight
- Individual precision collimating optics collects and redirect light to optimize performance
- Functions in environments with temperatures that range from -30°C to 40°C (-22°F to 104°F)

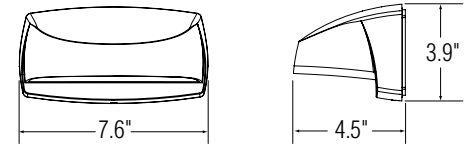

ELECTRICAL

- Electronic Class II LED driver accepts 120-220v, 50/60Hz input (constant current)
- Requires only 13 system watts for environmentally-friendly operation

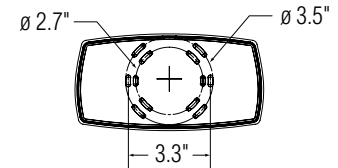

MOUNTING

- Built-in bubble level for accuracy
- Universal mounting plate with hook and lock mounting

WARRANTY/LISTINGS

 
 
- ETL tested suitable for wet location
- Five year warranty

OPTIONS

- Optional field installed PCB1 photocontrol for automatic dusk-to-dawn lighting



Ordering Guide Example: GSM7T




Prefix

Finish

GSM7=GeoScapes Mini Architectural LED Wall Sconce

T=Titanium Gray
W=White

PHOTOMETRIC DATA

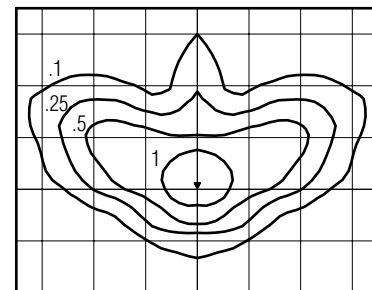

Horizontal Footcandles
 Light Loss Factor = 1.00
 Luminaire Lumens = 555
 Mounting Height = 8.00 Ft
 Maximum Calculated Value = 1.82 Fc



Listed for wet locations



2345 Vauxhall Road - P.O. Box 129
 Union, NJ 07083
 800-334-2212
 www.exceline.com

ExcelLine is a Philips group brand

Product information is subject to change without notice

