

# PATHLYTES



## AVS3 ALUMINUM

AVS3-A Black (matte)    AVS3-G Verde (matte)  
AVS3-H Bronze (matte)

- 120 Volt
- 60 watt maximum
- A19 Lamp
- 1/2" NPS fitter
- Stem not included, order separately

**HOUSING** – Cast aluminum cage and decorative arm.

**FINISH** – Black thermoset, bronze, hand-rubbed verde antiqued over black thermoset powdercoat.

**LENS** – Clear polycarbonate fresnel lens.

**SOCKET** – Inverted porcelain medium base.


**WIRING** – Incandescent fixtures are pre-wired with high temperature #18 wire.

ETL, cETL Listed.

### Optional Stems

Catalog No.	Finish	Description
S12	(Specify)*	Stem-12", 1/2" NPS
S24	(Specify)*	Stem-24", 1/2" NPS
S36	(Specify)*	Stem-36", 1/2" NPS

\*Specify Finishes: G-Verde, A-Black, H-Bronze

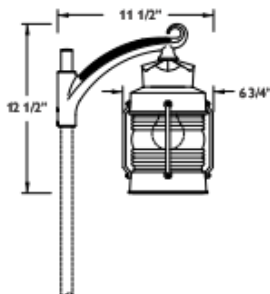

## AV3 ALUMINUM

AV3-A Black (matte)    AV3-G Verde (matte)  
AV3-H Bronze (matte)

- 120 Volt
- 60 watt maximum
- A19 Lamp
- 1/2" NPS fitter
- Stem not included, order separately

**HOUSING** – Cast aluminum cage and decorative roof.

**FINISH** – Hand-rubbed verde antiqued over black thermoset powdercoat.

**LENS** – Clear polycarbonate fresnel lens.

**SOCKET** – Porcelain medium base.


**WIRING** – Incandescent fixtures are pre-wired with high temperature #18 wire.

ETL, cETL Listed.

### Optional Stems

Catalog No.	Finish	Description
S12	(Specify)*	Stem-12", 1/2" NPS
S24	(Specify)*	Stem-24", 1/2" NPS
S36	(Specify)*	Stem-36", 1/2" NPS

\*Specify Finishes: G-Verde, A-Black, H-Bronze

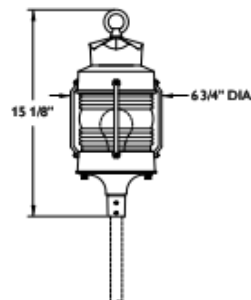

## A42 ALUMINUM

A42-G Verde    A42-U Sienna  
A42-T Speckled Stone

- 120 Volt
- 60 watt maximum
- A19 Lamp
- 1/2" NPS fitter
- Stem not included, order separately

**HOUSING** – Die-cast aluminum construction. Removable roofs for easy relamping.

**FINISH** – Hand-rubbed verde antiqued over black thermoset powdercoat. Speckled stone, or sienna thermoset powdercoat.

**LENS** – Opalescent glass panels, removable for cleaning.

**SOCKET** – Porcelain medium base.


**WIRING** – Incandescent fixtures are pre-wired with high temperature #18 wire.

ETL, cETL Listed.

### Optional Stems

Catalog No.	Finish	Description
S12	(Specify)*	Stem-12", 1/2" NPS
S24	(Specify)*	Stem-24", 1/2" NPS
S36	(Specify)*	Stem-36", 1/2" NPS

\*Specify Finishes: G-Verde (shown), T-Speckled Stone, U-Sienna

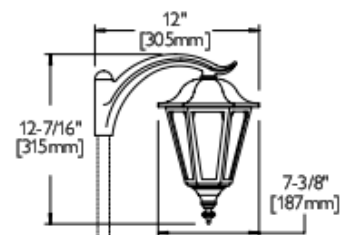

**PHILIPS**  
**HADCO**