


Aluminum Bullyte (BL1) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

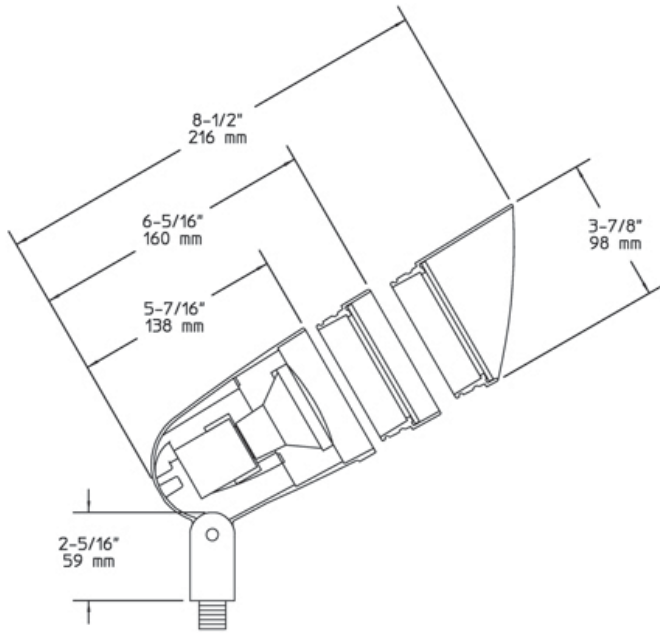

Ordering Guide

Example: BL1 A S S7

Product Code	BL1	Aluminum Bullyte
Finish	A H	Black Bronze
Shroud	S L	Short Shroud Long Shroud
Mounting	S7	Mounting Stake

Specifications

HOUSING:

Die-cast aluminum. Fully rotatable shroud, gasketed, cast aluminum. Fasteners are 300 series stainless steel. Fully-adjustable swivel arm with vibration-proof locking teeth. 1/2" NPS male threads to screw onto accessory mounting stake or junction box, sold separately.

FINISH:

Thermoset polyester powdercoat is electrostatically applied after a five-stage conversion cleaning process and bonded by heat fusion thermosetting.

OPTICAL ASSEMBLY:

Clear tempered glass lens.

LAMPING:

75W maximum MR16 bi-pin lamp. Covered MR16 are recommended to protect lamps inner capsule. Lower wattage lamps are acceptable. Lamp is not included.

ELECTRICAL ASSEMBLY:

Bi-pin socket type (GU5.3) with 250° C high temperature teflon coated wire leads. 12 Volt fixture is pre-wired with 3-ft pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.

WARRANTY:

Three-year limited warranty.

CERTIFICATIONS:

ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

Width:

3 7/8" (98mm)

Length:

8 1/2" (216mm)

Max. Weight:

1.4 lb