


Copper Decklyte (GADL2) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

Ordering Guide

Example: GADL2 AC

Product Code	GADL2	Copper Decklyte
Finish	AC	Hand-Crafted Copper

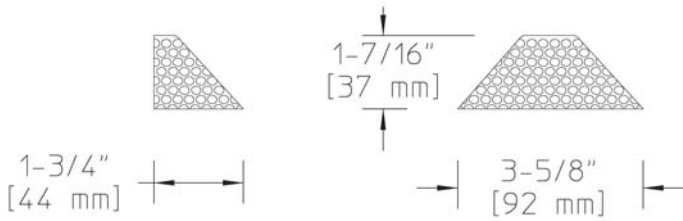

Specifications

HOUSING:

Hammered solid copper with copper back plate.

FINISH:

Antique Copper (AC) is a hand-applied dark copper patina.

LAMPING:

12W maximum wedge base T3-¼ lamp. 10W wedge base T3 ¼ (xenon) lamp is included with fixture. Xenon lamp life is approximately 10,000 hours. Lamp does not need to be protected and can be directly handled.

ELECTRICAL ASSEMBLY:

Wedge base socket type (T3-¼ or T5). 12 volt fixture is pre-wired with 6-ft. pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.

INSTALLATION & MOUNTING:

Two (2) Stainless #8 wood screws (supplied) via key slots.

WARRANTY:

Ten-year limited warranty.

CERTIFICATIONS:

ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

Height :

1 7/16" (37mm)

Width:

3 5/8" (92mm)

Depth:

1 3/4" (44mm)

Max. Weight:

0.3 lb