


Copper Pathlyte (GASL4) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

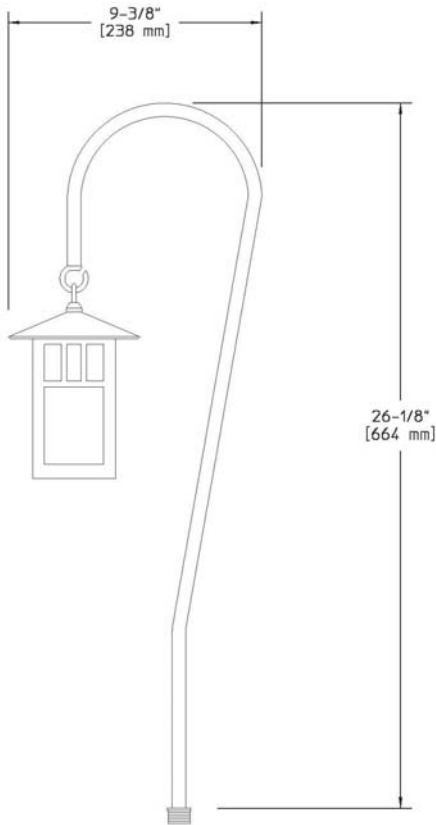

Ordering Guide

Example: GASL4 AC

Product Code	GASL4	Copper Pathlyte
Finish	AC	Hand-Crafted Copper

Spacing Chart

Recommended Spacing - GASL4-AC - 10'
Horizontal footcandles

Volt/Lamp	1'	2'	3'	4'	5'	6'	7'	8'	9'
12V, 27W 1156	9.62	1.52	.46	.17	.10	.05	.03	-	-

Specifications

HOUSING:

Hand-formed solid copper and copper tubing. 1/2" NPS male threads to screw onto accessory mounting stake or junction box, sold separately.

FINISH:

Antique Copper (AC) is a hand-applied dark copper patina.

OPTICAL ASSEMBLY:

Honey colored iridized art glass.

LAMPING:

Lamp is included with fixture. 27W maximum S-8 (1156) lamp. Lower wattage lamps are acceptable.

ELECTRICAL ASSEMBLY:

Single contact bayonet (S-8). 12 Volt fixture is pre-wired with 3-ft pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.

WARRANTY:

Ten-year limited warranty.

CERTIFICATIONS:

ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

Height :

26 1/8" (664mm)

Width:

9 3/8" (238mm)

Copper Pathlyte (GASL4) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

Max. Weight:
4.84 lb.