


# Aluminum Pathlyte (RL4) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

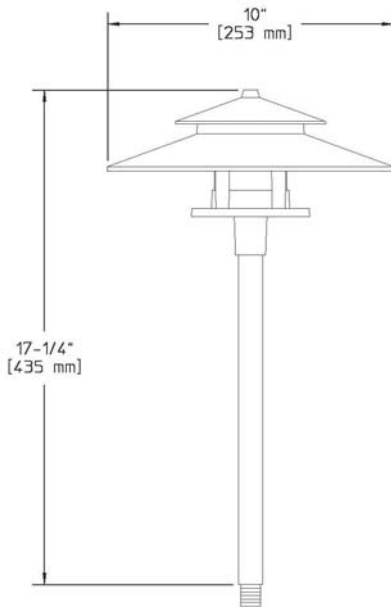

## Ordering Guide

Example: RL4 H S7

<b>Product Code</b>	RL4	Aluminum Pathlyte
<b>Finish</b>	H A G	Bronze Black Verde
<b>Mounting</b>	S7	Mounting Stake *1

\*1 Mounting stake option only available with Black and Verde Pathlytes.

## Specifications

### HOUSING:

Die-cast aluminum. Stem is extruded aluminum. Fasteners are 300 series stainless steel. 1/2" NPS male threads to screw onto accessory mounting stake or junction box, sold separately.

### FINISH:

Thermoset polyester powdercoat is electrostatically applied after a five-stage conversion cleaning process and bonded by heat fusion thermosetting. Laboratory tested for superior weatherability and fade resistance in accordance with ASTM B117 specifications.

### OPTICAL ASSEMBLY:

Frosted tempered glass lens. Spun aluminum reflector with white thermoset powdercoat.

### LAMPING:

20W maximum T3 bi-pin lamp. Lamp is included with fixture. Lower wattage lamps are acceptable.

### ELECTRICAL ASSEMBLY:

Bi-pin socket type (G4) with 250° C high temperature teflon coated wire leads. 12 Volt fixture is pre-wired with 3-ft pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.

### WARRANTY:

Three-year limited warranty.

### CERTIFICATIONS:

ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

### Height :

17 1/4" (435mm)

### Width:

10" (253mm)

### Max. Weight:

3.18 lb.