

e-Vision Low Wattage 20-150W

E-VISION ELE MH BAL 150W M102/142 120-277V

Low frequency electronic HID ballasts such as the Philips Advance e-Vision line constantly measure and adjust the wattage, optimizing delivery of the ceramic lamps' superior color properties. This makes ceramic metal halide operated by e-Vision ballasts the premier choice for many applications previously illuminated by either tungsten halogen or incandescent sources, such as retail lighting.

Product data

• General Characteristics

Lamp Type	150W MH
Number of Lamps	1 piece
Input Voltage	120-277 V
Line Frequency	50/60 Hz
Ballast Type	Electronic HID
Base Model	IMH150HLF
Housing	H
Housing Dimensions	5.7" x 3.6" x 1.5"
Housing Material	Metal
Suitable for Outdoor use?	Yes
Lifetime 90% surv.@Tcaselife	50000 hr
Family Name	eVision

• Operating Characteristics

Ignition time	1200 s
Input Power Gear	165-161 W
Ballast factor	1 -
Power Factor	0.90
Lamp Current Crest Factor	1.8 -
Sound Rating	A
Max THD	15 %

• Wiring Characteristics

Color input terminals	No terminals
Color output terminals	No terminals
Connector type	No connector
Wire Striplength	0.50 mm
Control Wire Gauge	NA
Wire Gauge	18AWG

Wire Length by Color	All leads = 11"
Wire Type	Stranded
Allowed Wiring Config(Remote)	Yes
Allowed Wiring Config(Tandem)	No
Allowed Wiring Config(Through)	No

• System Chars on driver level

Rated Lamp Watts	150
------------------	-----

• Temperature Characteristics

T-case maximum	85 C
----------------	------

• Product Dimensions

Length A1	6.3 in
Length A2	5.7 in
Length A3	6.0 in
Width B1	3.6 in
Height C1	1.5 in
Length A4	2.0 in
Width B2	2.9 in

• Approval & Application Chars

EMC Immunity	FCC Non-Consumer
CE marking	No
ENEC certificate	No
VDE certificate	No
UL Listed	Yes
CSA certificate	Yes
CEC Listing	No

PHILIPS

e-Vision Low Wattage 20-150W


CSA Recognized	No
cUL certificate	No
EISA	No
FIDE Certificate	No
NOM certificate	Yes
RoHS Compliant	Yes
SASO Certificate	No
UL Recognized	No
ANSI Code	C102/M102, C142/M142

Full product name	ELE MH BAL 150W M102/142 120-277V
Short product name	ELE MH BAL 150W M102/142 120-277V
Pieces per Sku	1
Skus/Case	6
Bar code on pack	781087055595
Bar code on case	50781087055606
Logistics code(s)	913710295902
eop_net_weight_pp	0.885 kg

• Product Data


Product number IMH150HLFM

Dimensional drawing

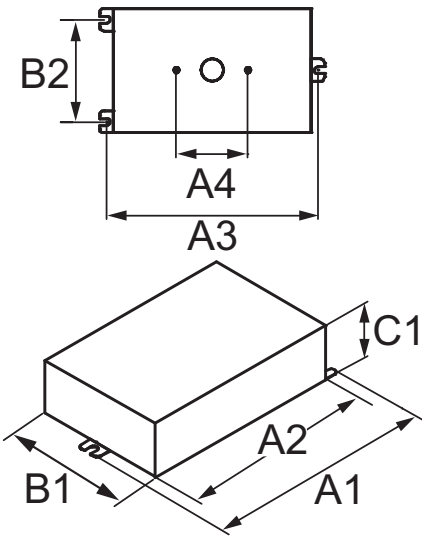

E-VISION ELE MH BAL 150W M102/142 120-277V

Product	A1 (Norm)	A2 (Norm)	A3 (Norm)	A4 (Norm)	A5 (Norm)	B1 (Norm)	B2 (Norm)	C1 (Norm)
ELE MH BAL 150W M102/142 120-277V	6.3	5.7	6.0	2.0	-	3.6	2.9	1.5

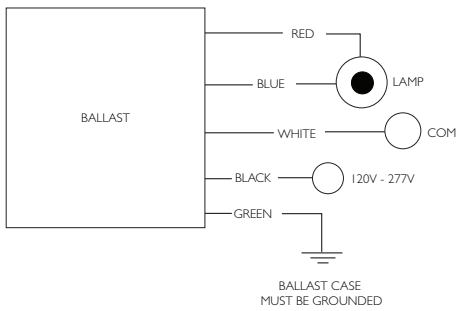

© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, February 1
data subject to change