

D.C. Bayonet

100Q/CL/DC ESR 120V 12PK



Accent lighting with improved lumens and higher performance. Halogen DC Bayonet Capsule lamps provide bright, white light for decorative and accent lighting and general illumination. Offered in T4 bulb size with DC Bayonette base configurations. These lamps offer a rated average life ranging from 1000 to 2000 hours depending upon the product. ** Rated average life is the length of operation (in hours) at which point an average of 50% of the lamps will still be operational and 50% will not.

Product data

• General Information

Cap-Base	Double Contact Bayonet [Double Contact Bayonet]
Bulb Shape	T4 [T4]
Operating Position	Universal [Universal]
Main Application	General Lighting (G)
Gas Filling	GAS

• Light Technical

Initial lumen (Nom)	1900 lm
Correlated Color Temperature (Nom)	2700 K
Color Rendering Index (Nom)	100

• Operating and Electrical

Power (Rated) (Nom)	100 W
---------------------	-------

Voltage (Nom) 120 V

• Mechanical and Housing

Bulb Finish	Clear (CL)
Cap-Base Information	Aluminium [Aluminium Cap]
Bulb Material	Standard Quartz
Filament Shape	CC-8 [Axial]

• Product Data

Order product name	DCBAY 100W 120V ESR 1CT/12
EAN/UPC - Product	046677115074
Order code	442780
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	924794736381
Net Weight (Piece)	0.009 kg

 
PHILIPS

Dimensional drawing


DC-BAY 100W 120V T4 Std-Q CL

Product

DCBAY 100W 120V ESR 1CT/12



BA15d, T-4

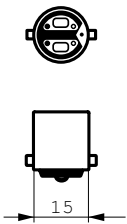

© 2015 Philips Lighting Holding B.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2015, November 29
data subject to change