



Mini-Candelabra

BC150Q/CL ETG 120V 12/1PK

Bright, white light with higher performance for accent lighting. Halogen Mini Candelabra T4 Capsule lamps provide bright, white light for decorative and accent lighting and general illumination. Offered in T4 bulb size with mini candelabra base configurations. These lamps offer a rated average life ranging from 1000 to 2000 hours depending upon the product.* Rated average life is the length of operation (in hours) at which point an average of 50% of the lamps will still be operational and 50% will not.

Product data

• General Information

Cap-Base	E11 [E11 Mini Candelabra]
Bulb Shape	T-4
Operating Position	UNIVERSAL [Any or Universal (U)]
Gas Filling	Gas

• Light Technical

Luminous Flux (Nom)	2800 lm
Correlated Color Temperature (Nom)	2800 K
Color Rendering Index (Nom)	100

• Operating and Electrical

Power (Rated) (Nom)	150 W
---------------------	-------

Voltage (Nom)	120 V
---------------	-------

• Mechanical and Housing

Bulb Finish	Clear
Filament Shape	CC-8 [Axial]

• Product Data

Order product name	BC150Q/CL ETG 120V 12/1PK
EAN/UPC - Product	046677416348
Order code	926000850097
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	926000850097
Net Weight (Piece)	0.009 kg


PHILIPS

Dimensional drawing


MINI CANDL 150W E11 120V T4 CC-8

Product

BC150Q/CL ETG 120V 12/1PK

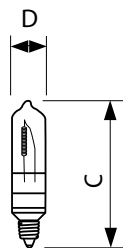

E11, T4

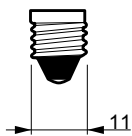

© 2015 Philips Lighting Holding B.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2015, November 29
data subject to change