



A-Shape LED

8.5A19/LED/827/ND 120V 2PK/4

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

• General Information

| | |
|------------------------|--|
| Cap-Base | E26 [E26 Single Contact Medium Screw] |
| Bulb Shape | A19 (A19) |
| Nominal Lifetime (Nom) | 10950 h |
| Switching Cycle | 50000X |
| Technical Type | 8.5-60W |

• Light Technical

| | |
|---------------------------------------|---------------------|
| Color Code | 827 [CCT of 2700K] |
| Luminous Flux (Nom) | 800 lm |
| Luminous Flux (Rated) (Nom) | 800 lm |
| Color Designation | Warm White (WW) |
| Correlated Color Temperature (Nom) | 2700 K |
| Luminous Efficacy (rated) (Nom) | 94 lm/W |
| Color Consistency | ANSI |
| Color Rendering Index (Nom) | 80 |
| LLMF At End Of Nominal Lifetime (Nom) | 70 % |

• Operating and Electrical

| | |
|---------------------|--------|
| Input Frequency | 60 Hz |
| Power (Rated) (Nom) | 8.5 W |
| Lamp Current (Nom) | 125 mA |
| Wattage Equivalent | 60 W |

| | |
|---------------------------------|-------|
| Starting Time (Max) | 0.5 s |
| Warm Up Time To 60% Light (Nom) | 0.5 s |
| Power Factor (Nom) | 0.5 |
| Voltage (Nom) | 120 V |

• Temperature

| | |
|----------------------|--------|
| T-Case Maximum (Nom) | 100 °C |
|----------------------|--------|

• Controls and Dimming

| | |
|----------|----|
| Dimmable | No |
|----------|----|

• Mechanical and Housing

| | |
|-------------|---------|
| Bulb Finish | Frosted |
|-------------|---------|

• Approval and Application


| | |
|------------------------------|----|
| Suitable For Accent Lighting | No |
|------------------------------|----|

• Product Data

| | |
|---------------------------------|------------------------------|
| Order product name | 8.5A19/LED/827/ND 120V 2PK/4 |
| Order code | 929001135034 |
| Numerator - Quantity Per Pack | 1 |
| Numerator - Packs per outer box | 4 |
| Material Nr. (12NC) | 929001135034 |
| Net Weight (Piece) | 0.052 kg |

PHILIPS

Dimensional drawing

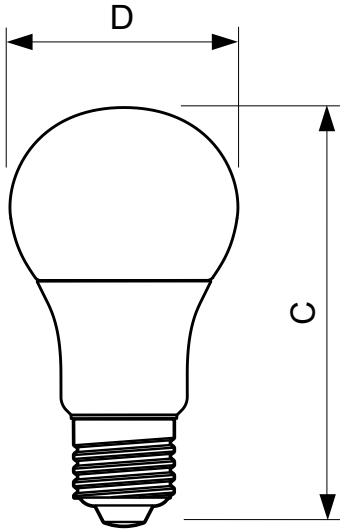


E26 A19

Bulb A19 120V 8.5W-60W 150D 2700K E26 ND


| Product | D | C |
|------------------------------|---------|----------|
| 8.5A19/LED/827/ND 120V 2PK/4 | 61.0 mm | 107.4 mm |

Photometric data

General Uniform Lighting

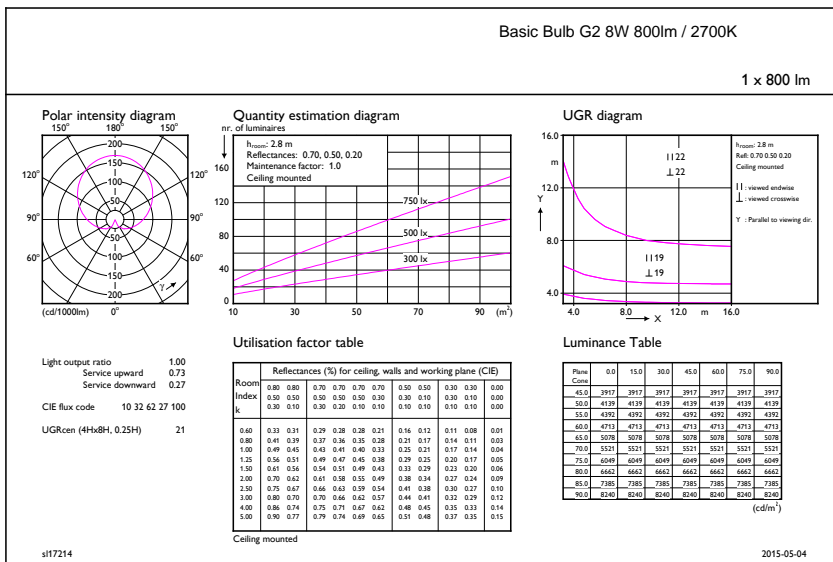

A-Shape LED

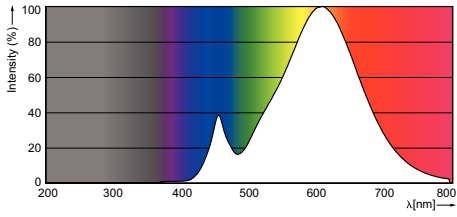

© 2016 Philips Lighting Holding B.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2016, July 20
data subject to change