



# PAR38 LED Series 1200

17PAR38/END/F25 3000-1050 OD 6/1

Philips PAR38 Series 1200 Dimmable LED Lamps with smooth dimming are perfect for track and recessed lighting. Their performance provides more light where you need it.

## Product data

### • General Characteristics

Cap-Base	E26
Bulb	PAR38 [PAR38 mm]
Bulb Finish	Grey
Rated Avg. Life (Hours)	45000 hr

### • Light Technical Characteristics

Color Code	WH
Color Designation	White
Beam Angle	25 D
Beam Description	- [-]
Correlated Color Temperature	3000 K
Approx. MBCP	4100 cd
CRI	80
Color Temp. (Kelvin)	3000 K [CCT 3000K]
Rated Luminous Flux	1050 Lm

### • Electrical Characteristics

Wattage	18 W
Wattage Technical	18.0 W
Voltage	120 V

Line Frequency	60 Hz
Power Factor	0.72 -
Lamp Current mA	196 mA
Dimmable	Yes

### • Product Dimensions

Overall Length C [inch]	5.319 (max) in
-------------------------	----------------

### • Product Data


Product number	418558
Full product name	17PAR38/END/F25 3000-1050 OD 6/1
Short product name	17PAR38/END/F25 3000-1050 OD 6/1
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677418557
Bar code on case	50046677418552
Logistics code(s)	929000202404
eop_net_weight_pp	0.528 kg

## Dimensional drawing



# PHILIPS

Dimensional drawing

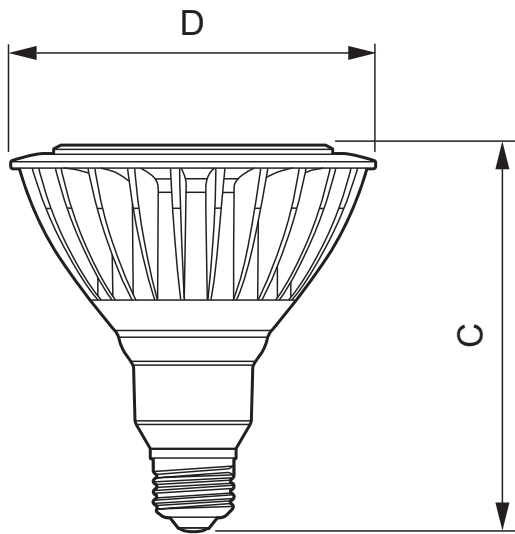

17PAR38/END/F25 3000-1050 OD 6/1

Product	C (Norm)	D (Norm)
LED 18W 3000K 120V PAR38 Grey 25D OD	-	-



E26



© 2013 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2013, June 22  
data subject to change