



# Candle LED

## 7F15/LED/827-22/E26/DIM 120V

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

### Product data


General Information		Warm Up Time To 60% Light (Nom)	
Cap-Base	E26 [ Single Contact Medium Screw]		instant full light
Nominal Lifetime (Nom)	25000 h	Power Factor (Nom)	0.9
Switching Cycle	50000X	Voltage (Nom)	120 V
Technical Type	7-60W	<b>Temperature</b>	
<b>Light Technical</b>		T-Case Maximum (Nom)	100 °C
Color Code	822-827 [ tunable warm white]	<b>Controls and Dimming</b>	
Luminous Flux (Nom)	500 lm	Dimmable	Yes
Luminous Flux (Rated) (Nom)	500 lm	<b>Mechanical and Housing</b>	
Color Designation	Warm White (WW)	Bulb Finish	CL [ Clear (CL)]
Correlated Color Temperature (Nom)	2200-2700 K	<b>Approval and Application</b>	
Color Consistency	ANSI 2700K	Energy star mark	Energy star
Color Rendering Index (Nom)	80	Suitable For Accent Lighting	No
LLMF At End Of Nominal Lifetime (Nom)	70 %	Energy Efficiency Label (EEL)	Not applicable
<b>Operating and Electrical</b>		Energy Consumption kWh/1000 h	7 kWh
Input Frequency	60 Hz	<b>Product Data</b>	
Power (Rated) (Nom)	7 W	Order product name	7F15/LED/827-22/E26/DIM 120V
Lamp Current (Nom)	65 mA	EAN/UPC - Product	046677458638
Wattage Equivalent	60 W		
Starting Time (Nom)	0.5 s		

## Candle LED

Order code	458638
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001182204

Net Weight (Piece)	0.070 kg
--------------------	----------


### Dimensional drawing

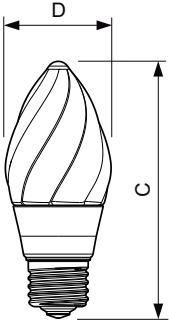

LED 7-60W E26 F15 CL DIM

Product	D	C
7F15/LED/827-22/E26/DIM 120V	46 mm	113 mm

### Photometric data

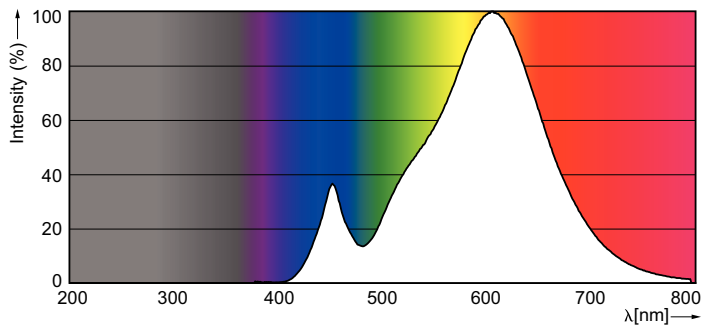

CorePro 822-827

