



MasterColor CDM ED17 Protected Elite 4200K

MasterColor CDM 50W ED17P CL U ELITE/4K

MasterColor Elite Protected Ceramic Metal Halide ED-17 4200K
Lamps provide excellent lumen maintenance and outstanding performance over time in a protected lamp.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Brass [Brass Base]
Bulb	ED17P [Protected]
Bulb Material	Hard Glass
Bulb Finish	Clear
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
RatedAvgLife(See Family Notes)	20000 hr

Lamp Voltage	88 V
Lamp Current	0.67 A
Ignition Time	10 (max) s
Re-ignition Time [min]	8 (max) min

• Environmental Characteristics

Mercury (Hg) Content	5.6 (max) mg
Picogram per Lumen Hour	76 p/LuHr

• Light Technical Characteristics

Color Code	940 [CCT of 4000K]
Color Rendering Index	86 (min), 90 (nom) Ra8
Color Designation	Cool White
Color Temperature	4000 K
Color Temperature technical	4100 K
Initial Lumens	4600 Lm
Luminous Efficacy Lamp	92 Lm/W
Lumen Maintenance - 10% life	90 %
Lumen Maintenance - 40% life	80 %
Design Mean Lumens	3680 Lm
Chromaticity Coordinate X	0.365 (min), 0.374 (nom), 0.383 (max)
Chromaticity Coordinate Y	0.364 (min), 0.370 (nom), 0.376 (max)

• UV-related Characteristics

Damage Factor D/fc	0.31 -
PET (NIOSH)	267 h500lx
UV A	10.1 mW/cm ²
UV B	0 mW/cm ²
UV C	0 mW/cm ²

• Luminaire Design Requirements

Cap-Base Temperature	190 (max) C
Bulb Temperature	400 (max) C

• Product Dimensions

Light Center Length L	3.438 in
Max Overall Length (MOL) - C	5.438 (max) in
Diameter D	2.125 in

• Electrical Characteristics

Watts	50 W
-------	------

MasterColor CDM ED17 Protected Elite 4200K

• Product Data


Product number 429944
Full product name MasterColor CDM 50W ED17P CL U ELITE/4K
Short product name MHC50/U/MP/4K ELITE
Pieces per Sku 1

Skus/Case 12
Bar code on pack 46677429942
Bar code on case 50046677429947
Logistics code(s) 928601177801
eop_net_weight_pp 0.001 kg

Dimensional drawing

MasterColor CDM 50W ED17P CL U ELITE/4K

Product	C (Max)	D (Norm)
MHC P 50W/940 E26 ED17P CL U ELITE	5.438	2.125

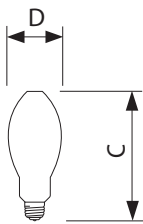

E26



© 2013 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2013, March 17
data subject to change