

# Knockout Hubs

## Knockout Hubs Technical Data


### ST

PIPE SIZE	CATALOG #	NOMINAL WEIGHT	A	B	C	MAX WALL THICK	ALUMINUM CATALOG #
1/2"	PRST1	0.2	1.34	2.00	0.81	0.125	PRSTA1
3/4"	PRST2	0.3	1.47	2.25	0.91	0.125	PRSTA2
1"	PRST3	0.4	1.66	2.50	1.03	0.125	PRSTA3
1-1/4"	PRST4	0.4	1.69	3.25	1.03	0.125	PRSTA4
1-1/2"	PRST5	0.6	1.69	3.50	1.03	0.125	PRSTA5
2"	PRST6	1.2	1.75	4.25	1.09	0.125	PRSTA6
2-1/2"	PRST7	1.5	2.22	4.75	1.28	0.125	PRSTA7
3"	PRST8	2.1	2.31	5.25	1.38	0.125	PRSTA8
3-1/2"	PRST9	3.0	2.38	5.50	1.44	0.125	PRSTA9
4"	PRST10	3.5	2.44	6.25	1.50	0.125	PRSTA10
5"	PRST11	5.4	2.94	7.50	2.00	0.125	PRSTA11
6"	PRST12	6.9	3.00	8.50	2.00	0.125	PRSTA12

### STG

PIPE SIZE	CATALOG #	NOMINAL WEIGHT	A	B	C	MAX WALL THICK	ALUMINUM CATALOG #
1/2"	PRSTG1	0.2	1.34	2.00	0.81	0.125	PRSTAG1
3/4"	PRSTG2	0.3	1.47	2.25	0.91	0.125	PRSTAG2
1"	PRSTG3	0.4	1.66	2.50	1.03	0.125	PRSTAG3
1-1/4"	PRSTG4	0.4	1.69	3.25	1.03	0.125	PRSTAG4
1-1/2"	PRSTG5	0.6	1.69	3.50	1.03	0.125	PRSTAG5
2"	PRSTG6	1.2	1.75	4.25	1.09	0.125	PRSTAG6
2-1/2"	PRSTG7	1.5	2.22	4.75	1.28	0.125	PRSTAG7
3"	PRSTG8	2.1	2.31	5.25	1.38	0.125	PRSTAG8
3-1/2"	PRSTG9	3.0	2.38	5.50	1.44	0.125	PRSTAG9
4"	PRSTG10	3.5	2.44	6.25	1.50	0.125	PRSTAG10
5"	PRSTG11	5.4	2.94	7.50	2.00	0.125	PRSTAG11
6"	PRSTG12	6.9	3.00	8.50	2.00	0.125	PRSTAG12

## KNOCKOUT HUB CONFIGURATIONS

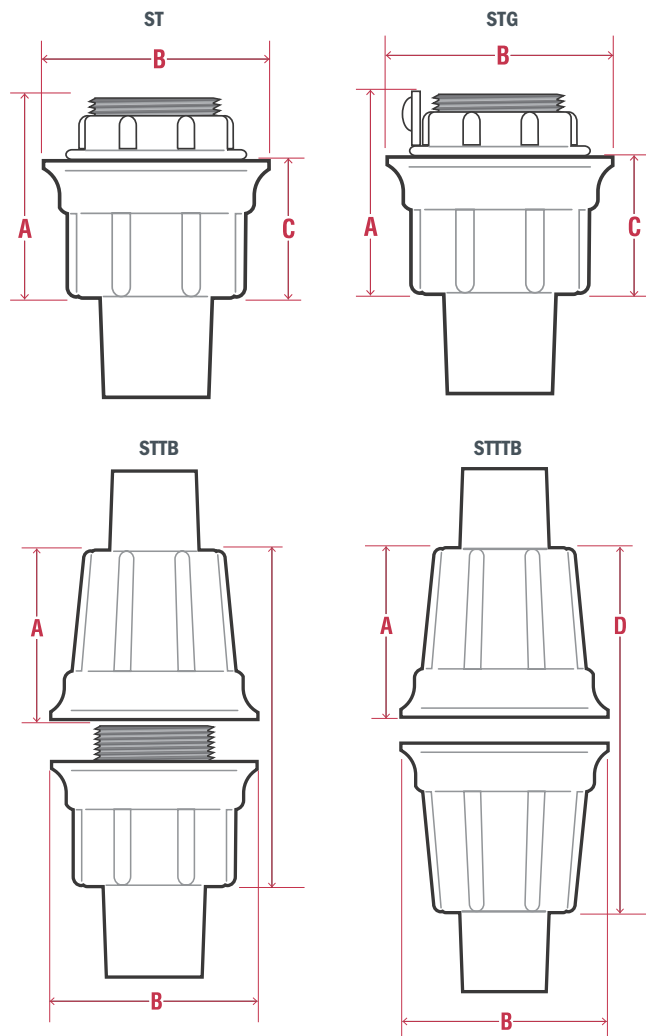

### STTB

PIPE SIZE	CATALOG #	NOMINAL WEIGHT	A	B	MAX WALL THICK	ALUMINUM CATALOG #
1/2"	PRSTTB1	0.5	1.34	2.00	0.19	PRSTTB1
3/4"	PRSTTB2	0.5	1.47	2.25	0.19	PRSTTB2
1"	PRSTTB3	0.7	1.66	2.50	0.25	PRSTTB3
1-1/4"	PRSTTB4	1.0	1.69	3.25	0.25	PRSTTB4
1-1/2"	PRSTTB5	1.2	1.69	3.50	0.25	PRSTTB5
2"	PRSTTB6	1.7	1.75	4.25	0.25	PRSTTB6
2-1/2"	PRSTTB7	2.5	2.22	4.75	0.25	PRSTTB7
3"	PRSTTB8	3.0	2.31	5.25	0.25	PRSTTB8
3-1/2"	PRSTTB9	4.2	2.38	5.50	0.25	PRSTTB9
4"	PRSTTB10	5.9	2.44	6.25	0.25	PRSTTB10

### STTTB

PIPE SIZE	CATALOG #	NOMINAL WEIGHT	A	B	MAX WALL THICK	ALUMINUM CATALOG #
1/2"	PRSTTTB1	1.0	1.34	2.00	*	PRSTTTB1
3/4"	PRSTTTB2	1.0	1.47	2.25	*	PRSTTTB2
1"	PRSTTTB3	1.4	1.66	2.50	*	PRSTTTB3
1-1/4"	PRSTTTB4	2.0	1.69	3.25	*	PRSTTTB4
1-1/2"	PRSTTTB5	2.4	1.69	3.50	*	PRSTTTB5
2"	PRSTTTB6	3.4	1.75	4.25	*	PRSTTTB6

\* Unlimited wall thickness - determined by nipple used.