

PLASTI-BOND REDH₂O_T SUPPORT PRODUCTS

PLASTI-BOND REDH₂O_T COATED PIPE STRAPS, CLAMP BACK SPACERS, AND THREAD RODS

[Print This Page](#)

Pipe Straps and Clamp Back Spacers Specifications

[Return To Index](#)

APPLICATION

PLASTI-BOND PVC coated pipe straps are used to securely mount conduit to a wall or other structure for support. They are available in two styles: a one-hole malleable iron strap or a two-hole stamped steel strap. Mounting hardware not provided.

PLASTI-BOND PVC coated clamp back spacers are used with malleable or stamped pipe straps to provide a mounting stand-off for a conduit from a wall or other structure.



FEATURES

- 20 mil gray PVC exterior coating
- 10 trade sizes from 1/2" through 4".

CONDUIT PIPE STRAP 1 HOLE SETS

Pipe Size	FERROUS Catalog #	Nominal Wt. For 100
<input type="checkbox"/> 1/2"	PBPS11M	11
<input type="checkbox"/> 3/4"	PBPS22M	14
<input type="checkbox"/> 1"	PBPS33M	12
<input type="checkbox"/> 1-1/4"	PBPS44M	25
<input type="checkbox"/> 1-1/2"	PBPS55M	36
<input type="checkbox"/> 2"	PBPS66M	71
<input type="checkbox"/> 2-1/2"	PBPS77M	111
<input type="checkbox"/> 3"	PBPS88M	134
<input type="checkbox"/> 3-1/2"	PBPS99M	166
<input type="checkbox"/> 4"	PBPS100M	256

CONDUIT PIPE STRAP 2 HOLE

Pipe Size	FERROUS Catalog #	Nominal Wt. For 100
<input type="checkbox"/> 1/2"	PBPS11S-2	2.0
<input type="checkbox"/> 3/4"	PBPS22S-2	3.0
<input type="checkbox"/> 1"	PBPS33S-2	4.0
<input type="checkbox"/> 1-1/4"	PBPS44S-2	4.5
<input type="checkbox"/> 1-1/2"	PBPS55S-2	5.0
<input type="checkbox"/> 2"	PBPS66S-2	10.0
<input type="checkbox"/> 2-1/2"	PBPS77S-2	13.0
<input type="checkbox"/> 3"	PBPS88S-2	17.0
<input type="checkbox"/> 3-1/2"	PBPS99S-2	20.0
<input type="checkbox"/> 4"	PBPS100S-2	25.0

CONDUIT CLAMP BACK SPACER

Pipe Size	FERROUS Catalog #	Nominal Wt. Each
<input type="checkbox"/> 1/2"	PBCLB-M50	0.1
<input type="checkbox"/> 3/4"	PBCLB-M75	0.1
<input type="checkbox"/> 1"	PBCLB-M100	0.1
<input type="checkbox"/> 1-1/4"	PBCLB-M125	0.2
<input type="checkbox"/> 1-1/2"	PBCLB-M150	0.2
<input type="checkbox"/> 2"	PBCLB-M200	0.3
<input type="checkbox"/> 2-1/2"	PBCLB-M250	1.0
<input type="checkbox"/> 3"	PBCLB-M300	1.7
<input type="checkbox"/> 4"	PBCLB-M400	2.0


Conduit Clamp Hangers Specifications

APPLICATION

PLASTI-BOND PVC coated conduit clamp hangers are used with threaded rod to securely suspend conduit runs supported from above. They are provided with stainless steel hardware.

FEATURES

- 20 mil gray PVC exterior coating
- 10 trade sizes from 1/2" through 4".

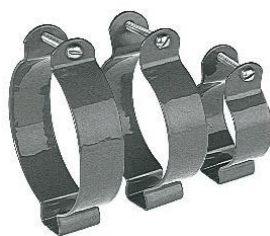

PB6HB Style

CONDUIT HANGER

Pipe Size	Catalog #	Nominal Weight
<input type="checkbox"/> 1/2"	PB6H0B	0.1
<input type="checkbox"/> 3/4"	PB6H1B	0.1
<input type="checkbox"/> 1"	PB6H2B	0.1
<input type="checkbox"/> 1-1/4"	PB6H3B	0.1
<input type="checkbox"/> 1-1/2"	PB6H4B	0.2
<input type="checkbox"/> 2"	PB6H5B	0.3
<input type="checkbox"/> 2-1/2"	PB6H6B	0.4
<input type="checkbox"/> 3"	PB6H7B	0.5
<input type="checkbox"/> 3-1/2"	PB6H8B	0.6
<input type="checkbox"/> 4"	PB6H9B	0.7

All Thread Rod Specifications

APPLICATION

PLASTI-BOND PVC coated all thread rod is used with coated conduit hangers and coated strut to securely suspend conduit runs supported from above. It is provided in 3/8" and 1/2" sizes and three standard lengths, 3', 6' and 10'.

FEATURES

- 20 mil gray PVC exterior coating
- 2 trade sizes and 3 standard lengths



PBH193

THREAD RODS

Size	Catalog #
<input type="checkbox"/> 3/8" X 3'	PBH193-3/8X3
<input type="checkbox"/> 3/8" X 6'	PBH193-3/8X6
<input type="checkbox"/> 3/8" X 10'	PBH193-3/8X10
<input type="checkbox"/> 1/2" X 3'	PBH193-1/2X3
<input type="checkbox"/> 1/2" X 6'	PBH193-1/2X6
<input type="checkbox"/> 1/2" X 10'	PBH193-1/2X10