


**Sealing Fittings Technical Data**

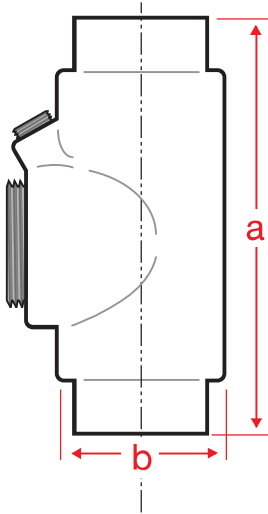

These PLASTI-BOND REDH<sub>2</sub>O<sub>T</sub> sealing fittings should be used with a suitable system of sealing compound, such as Chico A, Chico X or Chico A-P from Crouse-Hinds. Follow the installation instructions included with the sealing compound.

**EYS - FEMALE HUBS**

FOR SEALING IN VERTICAL POSITIONS ONLY

Pipe Size	FERROUS Catalog #	Nominal Weight	A	B	Turning Radius	Aluminum Catalog #
<input type="checkbox"/> 1/2"	PREYS1	1.0	4.28	1.33	1.63	PREYS1SA
<input type="checkbox"/> 3/4"	PREYS2	1.5	5.25	1.58	1.91	PREYS2SA
<input type="checkbox"/> 1"	PREYS3	2.1	6.31	1.83	2.38	PREYS3SA

FOR SEALING IN VERTICAL OR HORIZONTAL POSITIONS

<input type="checkbox"/> 1-1/4"	PREYS4	2.7	7.56	2.27	1.72	PREYS4SA
<input type="checkbox"/> 1-1/2"	PREYS5	3.7	8.50	2.52	2.06	PREYS5SA
<input type="checkbox"/> 2"	PREYS6	4.7	10.25	3.08	2.31	PREYS6SA
<input type="checkbox"/> 2-1/2"	PREYS7	10.0	11.50	3.58	2.69	PREYS7SA
<input type="checkbox"/> 3"	PREYS8	11.2	12.50	4.33	3.31	PREYS8SA
<input type="checkbox"/> 3-1/2"	PREYS9	14.5	13.19	4.83	3.44	PREYS9SA
<input type="checkbox"/> 4"	PREYS10	16.0	13.75	5.33	3.69	PREYS10SA

**EYS - MALE/FEMALE HUBS**

FOR SEALING IN VERTICAL POSITIONS ONLY

Pipe Size	FERROUS Catalog #	Nominal Weight	A	B	Turning Radius	Aluminum Catalog #
<input type="checkbox"/> 1/2"	PREYS16	1.5	4.78	1.33	1.63	PREYS16SA
<input type="checkbox"/> 3/4"	PREYS26	1.5	5.25	1.58	1.91	PREYS26SA
<input type="checkbox"/> 1"	PREYS36	2.3	6.31	1.83	2.38	PREYS36SA

**EYS - FEMALE HUBS**

FOR SEALING IN VERTICAL OR HORIZONTAL POSITIONS

Pipe Size	FERROUS Catalog #	Nominal Weight	A	B	Turning Radius	Aluminum Catalog #
<input type="checkbox"/> 1/2"	PREYS11	1.3	4.69	1.33	1.16	PREYS11SA
<input type="checkbox"/> 3/4"	PREYS21	1.1	5.19	1.58	1.25	PREYS21SA
<input type="checkbox"/> 1"	PREYS31	2.2	6.31	1.83	1.38	PREYS31SA
<input type="checkbox"/> 1-1/4"	PREYS41	3.0	7.56	2.27	1.72	PREYS41SA
<input type="checkbox"/> 1-1/2"	PREYS51	3.8	8.50	2.52	2.06	PREYS51SA
<input type="checkbox"/> 2"	PREYS61	5.5	10.25	3.08	2.31	PREYS61SA

**EYSX - EXPANDED FILL FEMALE HUBS FOR SEALING IN VERTICAL OR HORIZONTAL POSITIONS**

Pipe Size	FERROUS Catalog #	Nominal Weight	A	B	Turning Radius	Aluminum Catalog #
<input type="checkbox"/> 1/2"	PREYSX11	1.5	4.69	1.58	1.25	PREYSX1SA
<input type="checkbox"/> 3/4"	PREYSX21	2.1	5.81	1.83	1.38	PREYSX2SA
<input type="checkbox"/> 1"	PREYSX31	2.7	7.06	2.27	1.72	PREYSX3SA
<input type="checkbox"/> 1-1/4"	PREYSX41	3.7	8.75	3.08	2.31	PREYSX4SA
<input type="checkbox"/> 1-1/2"	PREYSX51	4.7	9.25	3.08	2.31	PREYSX5SA
<input type="checkbox"/> 2"	PREYSX61	6.7	12.50	4.33	3.31	PREYSX6SA
<input type="checkbox"/> 2-1/2"	PREYSX71	7.7	13.19	4.83	3.44	PREYSX7SA
<input type="checkbox"/> 3"	PREYSX81	8.7	13.75	5.33	3.69	PREYSX8SA
<input type="checkbox"/> 3-1/2"	PREYSX9	9.7	15.06	6.58	4.59	PREYSX9SA
<input type="checkbox"/> 4"	PREYSX10	10.7	15.06	6.58	4.59	PREYSX10SA

**EYS - MALE/FEMALE HUBS FOR SEALING IN VERTICAL OR HORIZONTAL POSITIONS**

Pipe Size	FERROUS Catalog #	Nominal Weight	A	B	Turning Radius	Aluminum Catalog #
<input type="checkbox"/> 1/2"	PREYS116	1.5	5.19	1.33	1.16	PREYS116SA
<input type="checkbox"/> 3/4"	PREYS216	1.2	5.19	1.58	1.25	PREYS216SA
<input type="checkbox"/> 1"	PREYS316	2.6	6.31	1.83	1.38	PREYS316SA
<input type="checkbox"/> 1-1/4"	PREYS46	2.8	7.56	2.27	1.72	PREYS46SA
<input type="checkbox"/> 1-1/2"	PREYS56	3.7	8.50	2.52	2.06	PREYS56SA
<input type="checkbox"/> 2"	PREYS66	5.6	10.25	3.08	2.31	PREYS66SA
<input type="checkbox"/> 2-1/2"	PREYS76	13.2	11.50	3.58	2.69	PREYS76SA
<input type="checkbox"/> 3"	PREYS86	11.2	12.50	4.33	3.31	PREYS86SA
<input type="checkbox"/> 3-1/2"	PREYS96	14.5	13.19	4.83	3.44	PREYS96SA
<input type="checkbox"/> 4"	PREYS106	1.5	13.75	5.33	3.69	PREYS96SA

Sealing Fittings continued on following pages...