

Plasti-Bond REDH₂O^T

Form 8 & Form 7 Conduit Bodies For General Service

Description:

Plasti-Bond conduit bodies with covers are offered in Form 8 and Form 7 styles, each with numerous configurations to provide a complete coated conduit system. May be used to make 90degree bends, for pull outlets, to provide for taps or splices, to act as a mounting outlet for wiring devices or lighting fixtures etc. Electrical continuity of the conduit system is maintained across assembled joints.

Features:

- 40 mil gray PVC exterior coating
- 2 mil red urethane internal coating
- 10 trade sizes from 1/2" through 4"
- Sealing sleeves on all conduit openings
- Form 7 style cover uses retained stainless screw and wedge clip design
- Form 8 style cover uses plastic encapsulated stainless steel screws with retainers built into covers for trade sizes 1/2" through 2".

Standards:

- UL Listed Standard 514B
- CSA Standard: C22.2 No. 18 Note: Form 7 fittings are not available with encapsulated screws. All cover screws are stainless steel. Form 8 fittings are shipped with encapsulated screws.



PRLB



PRT



PRL

Selected Product Numbers:
PRLR37

Product Charts:


Use the check boxes to 'flag or note' your selections for quick reference. Click the Button "Update Selections" to reflect changes.

Plasti-Bond REDH₂OT[®]

LL FORM 7

Edit Selection	Catalog Number	Size Inches	A	B	C	D	E	Weight	Aluminum Catalog Number
<input type="checkbox"/>	PRLL17	1/2"	5.1	1.42	2.29	0.94	3.19	1.2	PRLL17SA
<input type="checkbox"/>	PRLL27	3/4"	5.98	1.67	2.48	1.13	3.81	1.6	PRLL27SA
<input type="checkbox"/>	PRLL37	1"	7.04	1.92	2.79	1.38	4.5	2.1	PRLL37SA
<input type="checkbox"/>	PRLL47	1-1/4"	7.79	2.35	3.23	1.75	5	3	PRLL47SA
<input type="checkbox"/>	PRLL57	1-1/2"	8.67	2.6	3.6	1.94	5.44	4.1	PRLL57SA
<input type="checkbox"/>	PRLL67	2"	10.17	3.17	4.17	2.44	6.38	5.7	PRLL67SA
<input type="checkbox"/>	PRLL777	2-1/2"	12.54	3.67	5.79	3.56	8.38	10	PRLL777SA
<input type="checkbox"/>	PRLL87	3"	12.54	4.42	5.79	3.56	8.38	12.7	PRLL87SA
<input type="checkbox"/>	PRLL97	3-1/2"	14.73	4.92	6.98	4.5	10.25	19	PRLL97SA
<input type="checkbox"/>	PRLL107	4"	14.73	5.42	6.98	4.5	10.25	19	PRLL107SA

LR FORM 8

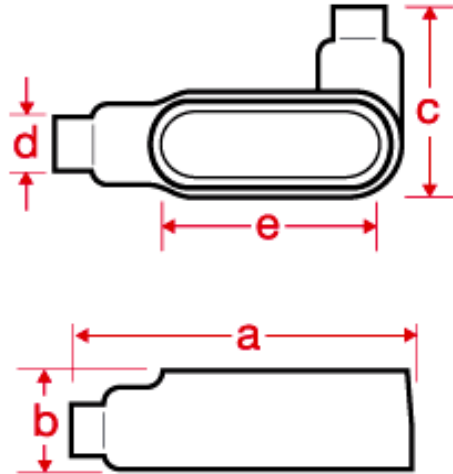

Edit Selection	Catalog Number	Size Inches	A	B	C	D	E	Weight	Aluminum Catalog Number
<input type="checkbox"/>	PRHLR18	1/2"	5.48	1.48	2.2	1	3.31	1.4	PRLR19
<input type="checkbox"/>	PRHLR28	3/4"	6.35	1.73	2.35	1.19	3.94	2.1	PRLR29
<input type="checkbox"/>	PRHLR38	1"	7.51	1.98	2.67	1.38	4.56	2.6	PRLR39
<input type="checkbox"/>	PRHLR448	1-1/4"	8.82	2.42	3.2	1.75	5.31	4.5	PRLR49


Plasti-Bond REDH₂OT[®]

<input type="checkbox"/>	PRHLR58	1-1/2"	10.67	2.82	4.04	2.13	6.5	6.2	PRLR59
<input type="checkbox"/>	PRHLR68	2"	13.04	3.6	5.04	3	8.56	10.7	PRLR69
<input type="checkbox"/>	PRLR78	2-1/2"	15.98	4.48	6.73	4.25	10.88	17.7	PRLR789
<input type="checkbox"/>	PRLR888	3"	15.98	4.85	6.73	4.25	10.88	18	PRLR889
<input type="checkbox"/>	PRLR989	3-1/2"	14.73	4.92	6.98	4.5	10.25	21	PRLR989
<input type="checkbox"/>	PRLR1089	4"	14.73	5.42	6.98	4.5	10.25	24	PRLR1089

LR FORM 7

Edit Selection	Catalog Number	Size Inches	A	B	C	D	E	Weight	Aluminum Catalog Number
<input type="checkbox"/>	PRLR17	1/2"	5.1	1.42	2.29	0.94	3.19	1.2	PRLR17SA
<input type="checkbox"/>	PRLR27	3/4"	5.98	1.67	2.48	1.13	3.81	1.6	PRLR27SA
<input checked="" type="checkbox"/>	PRLR37	1"	7.04	1.92	2.79	1.38	4.5	2.1	PRLR37SA
<input type="checkbox"/>	PRLR47	1-1/4"	7.79	2.35	3.23	1.75	5	3	PRLR47SA
<input type="checkbox"/>	PRLR57	1-1/2"	8.67	2.6	3.6	1.94	5.44	4.1	PRLR57SA
<input type="checkbox"/>	PRLR67	2"	10.17	3.17	4.17	2.44	6.38	5.7	PRLR67SA
<input type="checkbox"/>	PRLR777	2-1/2"	12.54	3.67	5.79	3.56	8.38	10	PRLR777SA
<input type="checkbox"/>	PRLR87	3"	12.54	4.42	5.79	3.56	8.38	12.7	PRLR87SA
<input type="checkbox"/>	PRLR97	3-1/2"	14.73	4.92	6.98	4.5	10.25	19	PRLR97SA
<input type="checkbox"/>	PRLR107	4"	14.73	5.42	6.98	4.5	10.25	19	PRLR107SA

TB FORM 8

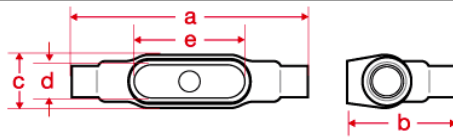

Edit Selection	Catalog Number	Size Inches	A	B	C	D	E	Weight	Aluminum Catalog Number
<input type="checkbox"/>	PRHTB18	1/2"	6.69	3.57	1.46	1	3.31	2	PRTB19
<input type="checkbox"/>	PRHTB28	3/4"	7.78	3.79	1.64	1.19	3.94	2.3	PRTB29
<input type="checkbox"/>	PRHTB38	1"	9.31	4.17	1.83	1.38	4.56	3.1	PRTB39
<input type="checkbox"/>	PRHTB448	1-1/4"	11	4.38	2.27	1.75	5.31	5.2	-