


PLASTI-BOND REDH₂O CONDUCIT BODIES

CONDUIT BODIES AND COVERS FOR GENERAL SERVICE LOCATIONS

Conduit Bodies Technical Data

Print This Page

Return To Index

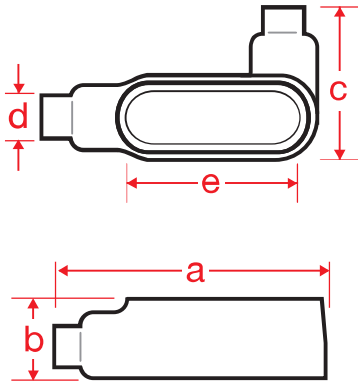

LR FORM 8

| Pipe Size | FERROUS CATALOG # | Nominal Weight | A | B | C | D | E | ALUMINUM CATALOG # |
|-----------|-------------------|----------------|-------|------|------|------|-------|--------------------|
| 1/2" | PRHLR18 | 1.4 | 5.48 | 1.48 | 2.20 | 1.00 | 3.31 | PRLR19 |
| 3/4" | PRHLR28 | 2.1 | 6.35 | 1.73 | 2.35 | 1.19 | 3.94 | PRLR29 |
| 1" | PRHLR38 | 2.6 | 7.51 | 1.98 | 2.67 | 1.38 | 4.56 | PRLR39 |
| 1-1/4" | PRHLR448 | 4.5 | 8.82 | 2.42 | 3.20 | 1.75 | 5.31 | PRLR49 |
| 1-1/2" | PRHLR58 | 6.2 | 10.67 | 2.82 | 4.04 | 2.13 | 6.50 | PRLR59 |
| 2" | PRHLR68 | 10.7 | 13.04 | 3.60 | 5.04 | 3.00 | 8.56 | PRLR69 |
| 2-1/2" | PRLR78 | 17.7 | 15.98 | 4.48 | 6.73 | 4.25 | 10.88 | PRLR789 |
| 3" | PRLR888 | 18.0 | 15.98 | 4.85 | 6.73 | 4.25 | 10.88 | PRLR889 |
| 3-1/2" | PRLR989 | 21.0 | 14.73 | 4.92 | 6.98 | 4.50 | 10.25 | PRLR989 |
| 4" | PRLR1089 | 24.0 | 14.73 | 5.42 | 6.98 | 4.50 | 10.25 | PRLR1089 |

LR FORM 7

| Pipe Size | FERROUS CATALOG # | Nominal Weight | A | B | C | D | E | ALUMINUM CATALOG # |
|-----------|-------------------|----------------|-------|------|------|------|-------|--------------------|
| 1/2" | PRLR17 | 1.2 | 5.10 | 1.42 | 2.29 | 0.94 | 3.19 | PRLR17SA |
| 3/4" | PRLR27 | 1.6 | 5.98 | 1.67 | 2.48 | 1.13 | 3.81 | PRLR27SA |
| 1" | PRLR37 | 2.1 | 7.04 | 1.92 | 2.79 | 1.38 | 4.50 | PRLR37SA |
| 1-1/4" | PRLR47 | 3.0 | 7.79 | 2.35 | 3.23 | 1.75 | 5.00 | PRLR47SA |
| 1-1/2" | PRLR57 | 4.1 | 8.67 | 2.60 | 3.60 | 1.94 | 5.44 | PRLR57SA |
| 2" | PRLR67 | 5.7 | 10.17 | 3.17 | 4.17 | 2.44 | 6.38 | PRLR67SA |
| 2-1/2" | PRLR777 | 10.0 | 12.54 | 3.67 | 5.79 | 3.56 | 8.38 | PRLR777SA |
| 3" | PRLR87 | 12.7 | 12.54 | 4.42 | 5.79 | 3.56 | 8.38 | PRLR87SA |
| 3-1/2" | PRLR97 | 19.0 | 14.73 | 4.92 | 6.98 | 4.50 | 10.25 | PRLR97SA |
| 4" | PRLR107 | 19.0 | 14.73 | 5.42 | 6.98 | 4.50 | 10.25 | PRLR107SA |




PRHT28



PRT27



Form 8 & Form 7 Covers

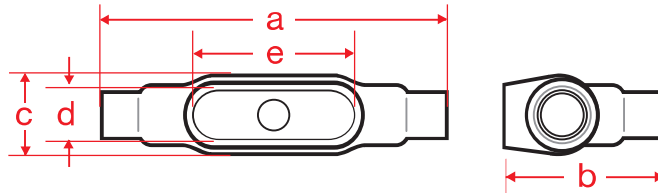

TB FORM 8

MARK 9

| Pipe Size | FERROUS CATALOG # | Nominal Weight | A | B | C | D | E | ALUMINUM CATALOG # |
|-----------|-------------------|----------------|-------|------|------|------|------|--------------------|
| 1/2" | PRHTB18 | 2.0 | 6.69 | 3.57 | 1.46 | 1.00 | 3.31 | PRTB19 |
| 3/4" | PRHTB28 | 2.3 | 7.78 | 3.79 | 1.64 | 1.19 | 3.94 | PRTB29 |
| 1" | PRHTB38 | 3.1 | 9.31 | 4.17 | 1.83 | 1.38 | 4.56 | PRTB39 |
| 1-1/4" | PRHTB448 | 5.2 | 11.00 | 4.38 | 2.27 | 1.75 | 5.31 | - |
| 1-1/2" | PRHTB58 | 7.0 | 13.38 | 5.07 | 2.83 | 2.13 | 6.50 | - |
| 2" | PRHTB68 | 11.0 | 16.25 | 5.85 | 3.83 | 3.00 | 8.56 | - |

TB FORM 7

| Pipe Size | FERROUS CATALOG # | Nominal Weight | A | B | C | D | E | ALUMINUM CATALOG # |
|-----------|-------------------|----------------|-------|------|------|------|------|--------------------|
| 1/2" | PRTB17 | 1.6 | 6.63 | 2.67 | 1.64 | 0.94 | 3.19 | PRTB19 |
| 3/4" | PRTB27 | 2.1 | 7.75 | 2.92 | 1.83 | 1.13 | 3.81 | PRTB29 |
| 1" | PRTB37 | 2.7 | 9.25 | 3.29 | 2.08 | 1.38 | 4.50 | PRTB39 |
| 1-1/4" | PRTB47 | 3.7 | 9.94 | 3.35 | 2.27 | 1.75 | 5.00 | - |
| 1-1/2" | PRTB57 | 4.7 | 11.19 | 5.04 | 2.52 | 1.94 | 5.44 | - |
| 2" | PRTB67 | 7.0 | 13.19 | 6.17 | 3.08 | 2.44 | 6.38 | - |