



# PLASTI-BOND REDH<sub>2</sub>O<sup>T</sup> CAST DEVICE BOXES AND COVERS

## DEVICE BOX COVERS

FS/FD Single Gang Cover Configurations

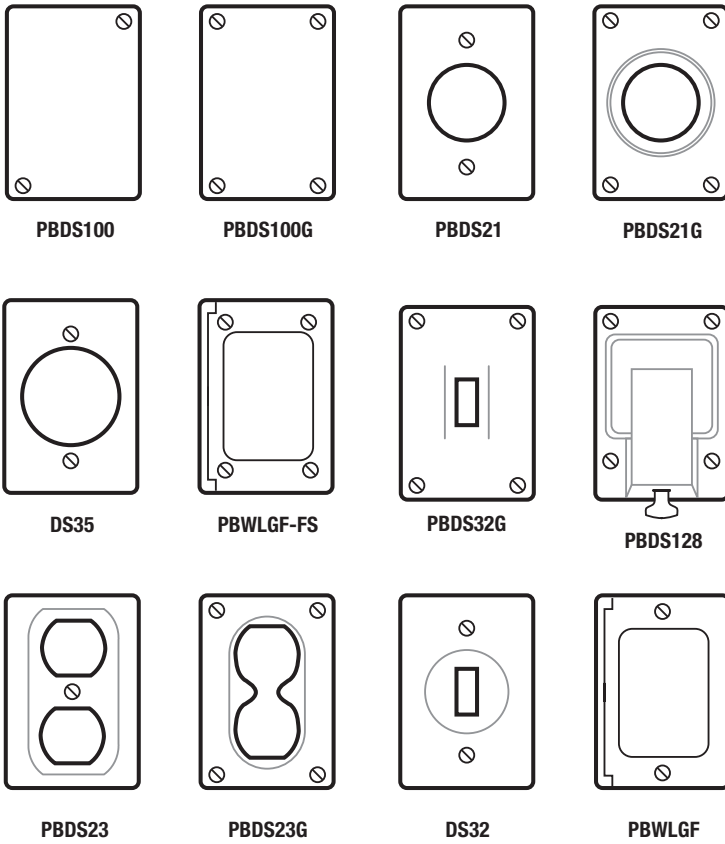

FS/FD 2 Gang Cover Configurations

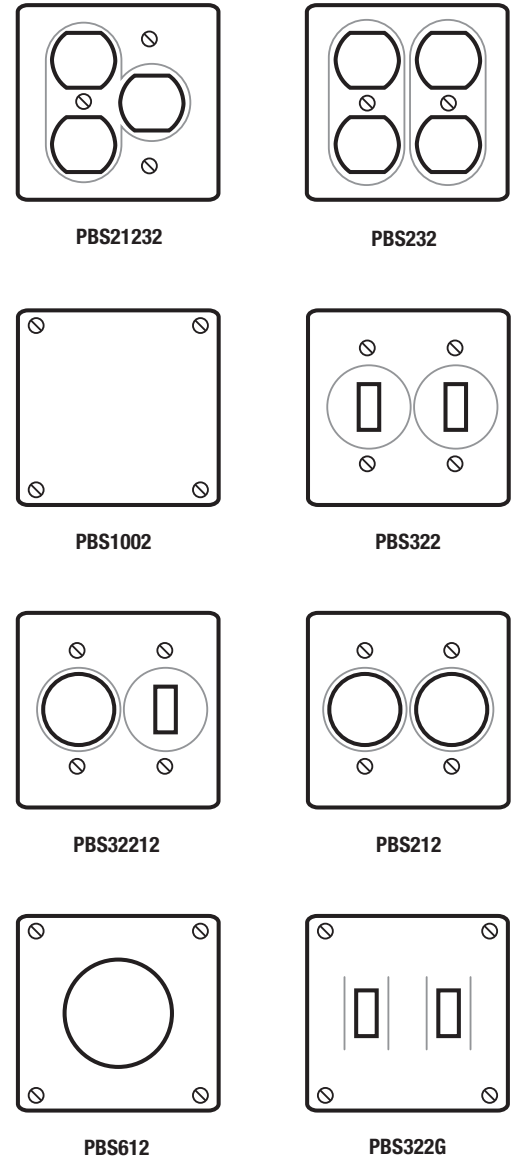

### FERROUS COVERS - SINGLE GANG

CATALOG #	Description	Nominal Weight
PBDS32	FS/FD 1 GANG COVER	0.4
PBDS23G	FS/FD 1 GANG COVER	0.4
PBDS35	FS/FD 1 GANG COVER	0.4
PBDS21	FS/FD 1 GANG COVER	0.3
PBDS21G	FS/FD 1 GANG COVER	0.3
PBDS23	FS/FD 1 GANG COVER	0.3
PBDS32G	FS/FD 1 GANG COVER	0.2

### ALUMINUM COVERS

CATALOG #	Description	Nominal Weight
PBDS23SA	FS/FD 1 GANG COVER AL	0.1
PBDS100	FS/FD 1 GANG AL COVER	0.1
PBDS128	FS/FD 1 GANG AL COVER	0.5
PBDS100G	FS/FD 1 GANG AL COVER	0.3
PRWLRD1	FS/FD 1 GANG AL DUPLEX COVER	0.4
PRWLR1	FS/FD 1 GANG AL COVER	0.3
PRWLR2	FS/FD 1 GANG AL COVER	0.3
PBS1002G	FS/FD 2 GANG COVER BLANK AL	0.5
PBWLG-FS	FS/FD COVER FOR GFCI RECEPTACLE	0.5
PBWLG-F	FS/FD COVER FOR GFCI RECEPTACLE	0.5

### FERROUS COVERS - TWO GANG

CATALOG #	Description	Nominal Weight
PBS1002	FS/FD 2 GANG COVER BLANK	1.0
PBS1002G	FS/FD 2 GANG COVER BLANK	1.0
PBS21232	FS/FD 2 GANG COVER	1.2
PBS232	FS/FD 2 GANG COVER	1.2
PBS322	FS/FD 2 GANG COVER	1.0
PBS32212	FS/FD 2 GANG COVER	1.2
PBS322	FS/FD 2 GANG COVER	1.0
PBS212	FS/FD 2 GANG COVER	2.0
PBS612	FS/FD 2 GANG COVER	1.2
PBS322G	FS/FD 2 GANG COVER	1.2

# PLASTI-BOND REDH<sub>2</sub>OT CAST DEVICE BOXES AND COVERS

## DEVICE BOXES



### FS/FD Series Specifications

#### APPLICATION

PLASTI-BOND REDH<sub>2</sub>OT device boxes and covers are available in several configurations and may be used in coated conduit systems to accommodate wiring devices, to serve as pull boxes for conductors, or to allow for splices and taps in conductors. Covers are available separately. Electrical continuity of the conduit system is maintained across assembled joints.

#### FEATURES

- 40 mil gray PVC exterior coating
- 2 mil red urethane interior coating
- 3 trade sizes from 1/2" through 1"
- Available in Standard (PRFS) and Deep (PRFD) Styles
- Internal green grounding screw is standard
- Sealing sleeves on all conduit openings
- Flat molded PVC gasket mates with all standard covers

#### COMPLIANCES

- UL Listed Standard 514B
- CSA Standard: C22.2 No. 18

### **Four “Extra” Touches in the Battle Against Corrosion.**

- 1.) The special PVC formulation for Plasti-Bond REDH<sub>2</sub>OT includes Ultraviolet Light (UV) inhibitors. Laboratory tests, exposure testing, and actual service all support the fact that we have never had a UV-related failure of PVC in more than 30 years!
- 2.) Plasti-Bond REDH<sub>2</sub>OT's PVC sealing sleeves are sized so they fit tightly over the coated conduit when assembled. This keeps corrosive elements away from the threaded joints.
- 3.) All Form 8 conduit cover screws are made from stainless steel with a plastic encapsulated head...yet another way of providing maximum corrosion protection by providing a seal around the screw opening.
- 4.) Plasti-Bond REDH<sub>2</sub>OT fittings provide gasket seals to keep corrosives from getting into the conduit system through joints and openings, protecting the interior of the system from corrosion.

APPROVAL STAMP

FS/FD Series Technical Data and Covers  
continued on following pages...

# Plasti-Bond REDH<sub>2</sub>OT<sup>®</sup>

## PLASTI-BOND REDH<sub>2</sub>OT PRICE LIST • CONDUIT OUTLET BOXES FOR HAZARDOUS LOCATIONS

### Conduit Outlet Boxes with Covers Cost and Shipping Information

#### PLASTI-BOND REDH<sub>2</sub>OT DEVICE BOX COVERS – FERROUS

CATALOG NUMBER	DESCRIPTION	LIST PRICE	PER PRICING UNIT	WEIGHT PER PRICING UNIT	STANDARD PACK QTY	UPC	AVAIL. CODE
PBDS21	FS/FD 1 GANG COVER	34.86	EA	0.3	10	784011205530	1
PBDS21G	FS/FD 1 GANG COVER	39.51	EA	0.3	10	784011205547	1
PBDS23	FS/FD 1 GANG COVER	24.19	EA	0.2	10	784011205554	1
PBDS23G	FS/FD 1 GANG COVER	35.18	EA	0.4	10	784011205516	1
PBDS32	FS/FD 1 GANG COVER	26.03	EA	0.2	10	784011205509	2
PBDS32G	FS/FD 1 GANG COVER	33.33	EA	0.4	10	784011205561	1
PBDS35	FS/FD 1 GANG COVER	26.29	EA	0.4	10	784011205523	2
PBS1002	FS/FD 2 GANG COVER	22.15	EA	1.0	10	784011205646	3
PBS1002G	FS/FD 2 GANG COVER	27.73	EA	1.6	10	784011205653	3
PBS212	FS/FD 2 GANG COVER ROUND SHEET STEEL	21.59	EA	2.0	10	784011205714	3
PBS21232	FS/FD 2 GANG COVER	21.87	EA	1.2	10	784011205660	3
PBS232	FS/FD 2 GANG COVER	23.81	EA	1.2	10	784011205677	3
PBS322	FS/FD 2 GANG COVER	24.47	EA	1.0	10	784011205684	3
PBS32212	FS/FD 2 GANG COVER SHEET STEEL	21.01	EA	1.2	10	784011205691	3
PBS322G	FS/FD 2 GANG COVER	35.75	EA	1.2	10	784011205738	3
PBS323	FS/FD 2 GANG COVER	17.41	EA	1.0	10	784011205707	3
PBS612	FS/FD 2 GANG COVER SHEET STEEL	26.78	EA	1.2	10	784011205721	3

#### PLASTI-BOND REDH<sub>2</sub>OT FERROUS BODY AND COVER

CATALOG NUMBER	DESCRIPTION	LIST PRICE	PER PRICING UNIT	WEIGHT PER PRICING UNIT	STANDARD PACK QTY	UPC	AVAIL. CODE
PROELB1	1/2 OELB BOX WITH COVER	108.05	EA	2.2	4	784011206438	3
PROELB2	3/4 OELB BOX WITH COVER	123.13	EA	3.0	4	784011206445	3
PROET1	1/2 OET BOX WITH COVER	113.08	EA	2.2	4	784011206452	3
PROET2	3/4 OET BOX WITH COVER	138.95	EA	3.0	4	784011206469	3

#### PLASTI-BOND REDH<sub>2</sub>OT FERROUS METAL BODIES WITH ALUMINUM COVERS

CATALOG NUMBER	DESCRIPTION	LIST PRICE	PER PRICING UNIT	WEIGHT PER PRICING UNIT	STANDARD PACK QTY	UPC	AVAIL. CODE
24 PRGUAB14	1/2 GUAB BODY WITH AL COVER	64.38	EA	2.0	4	784011205745	3
25 PRGUAB16	1/2 GUAB BODY WITH AL COVER	76.98	EA	3.2	4	784011205752	2
26 PRGUAB24	3/4 GUAB BODY WITH AL COVER	67.27	EA	2.2	4	784011205769	3
27 PRGUAB26	3/4 GUAB BODY WITH AL COVER	78.84	EA	3.3	4	784011205776	1
28 PRGUAB36	1 GUAB BODY WITH AL COVER	79.41	EA	3.8	4	784011205783	1
29 PRGUAB47	1-1/4 GUAB BODY WITH AL COVER	124.44	EA	5.0	4	784011205790	3
30 PRGUAB59	1-1/2 GUAB BODY WITH AL COVER	226.81	EA	8.1	4	784011205806	3
31 PRGUAB69	2 GUAB BODY WITH AL COVER	238.97	EA	9.1	4	784011205813	3
32 PRGUAC14	1/2 GUAC BODY WITH AL COVER	64.38	EA	2.0	4	784011205820	3
33 PRGUAC16	1/2 GUAC BODY WITH AL COVER	76.98	EA	3.5	4	784011205837	3
34 PRGUAC24	3/4 GUAC BODY WITH AL COVER	67.27	EA	2.0	4	784011205844	3
35 PRGUAC26	3/4 GUAC BODY WITH AL COVER	78.84	EA	3.5	4	784011205851	1
36 PRGUAC36	1 GUAC BODY WITH AL COVER	79.41	EA	3.9	4	784011205868	1
37 PRGUAC47	1-1/4 GUAC BODY WITH AL COVER	124.44	EA	5.2	4	784011205875	3
38 PRGUAC49	1-1/4 GUAC BODY WITH AL COVER	221.95	EA	9.5	4	784011205882	3
39 PRGUAC59	1-1/2 GUAC BODY WITH AL COVER	226.81	EA	11.0	4	784011205899	3
40 PRGUAC69	2 GUAC BODY WITH AL COVER	238.97	EA	11.0	4	784011205905	3

\*\*\* Consult factory

(continued on next page...)

AVAILABILITY CODES: 1 = NORMALLY STOCKED, 2 = TWO WEEKS, 3 = CONSULT FACTORY