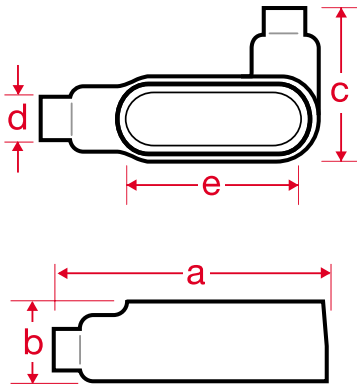


PLASTI-BOND REDH₂O T CONDUIT BODIES**CONDUIT BODIES FOR GENERAL SERVICE LOCATIONS****Conduit Bodies Technical Data**

APPROVAL STAMP

**LR FORM 8**

Pipe Size	FERROUS CATALOG #	Nominal Weight	A	B	C	D	E	ALUMINUM CATALOG #
1/2"	PRHLR18	1.4	5.48	1.48	2.20	1.00	3.31	PRLR19
3/4"	PRHLR28	2.1	6.35	1.73	2.35	1.19	3.94	PRLR29
1"	PRHLR38	2.6	7.51	1.98	2.67	1.38	4.56	PRLR39
1-1/4"	PRHLR448	4.5	8.82	2.42	3.20	1.75	5.31	PRLR49
1-1/2"	PRHLR58	6.2	10.67	2.82	4.04	2.13	6.50	PRLR59
2"	PRHLR68	10.7	13.04	3.60	5.04	3.00	8.56	PRLR69
2-1/2"	PRLR78	17.7	15.98	4.48	6.73	4.25	10.88	PRLR789
3"	PRLR888	18.0	15.98	4.85	6.73	4.25	10.88	PRLR889
3-1/2"	PRLR989	21.0	14.73	4.92	6.98	4.50	10.25	PRLR989
4"	PRLR1089	24.0	14.73	5.42	6.98	4.50	10.25	PRLR1089

LR FORM 7

Pipe Size	FERROUS CATALOG #	Nominal Weight	A	B	C	D	E	ALUMINUM CATALOG #
1/2"	PRLR17	1.2	5.10	1.42	2.29	0.94	3.19	PRLR17SA
3/4"	PRLR27	1.6	5.98	1.67	2.48	1.13	3.81	PRLR27SA
1"	PRLR37	2.1	7.04	1.92	2.79	1.38	4.50	PRLR37SA
1-1/4"	PRLR47	3.0	7.79	2.35	3.23	1.75	5.00	PRLR47SA
1-1/2"	PRLR57	4.1	8.67	2.60	3.60	1.94	5.44	PRLR57SA
2"	PRLR67	5.7	10.17	3.17	4.17	2.44	6.38	PRLR67SA
2-1/2"	PRLR777	10.0	12.54	3.67	5.79	3.56	8.38	PRLR777SA
3"	PRLR87	12.7	12.54	4.42	5.79	3.56	8.38	PRLR87SA
3-1/2"	PRLR97	19.0	14.73	4.92	6.98	4.50	10.25	PRLR97SA
4"	PRLR107	19.0	14.73	5.42	6.98	4.50	10.25	PRLR107SA




PRHT28



PRT27



Form 8 & Form 7 Covers

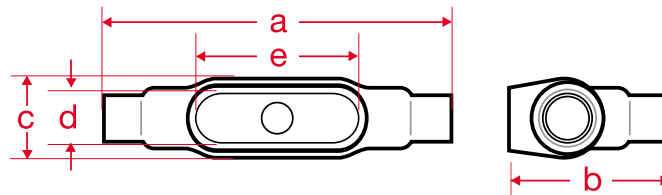**TB FORM 8****MARK 9**

Pipe Size	FERROUS CATALOG #	Nominal Weight	A	B	C	D	E	ALUMINUM CATALOG #
1/2"	PRHTB18	2.0	6.69	3.57	1.46	1.00	3.31	PRTB19
3/4"	PRHTB28	2.3	7.78	3.79	1.64	1.19	3.94	PRTB29
1"	PRHTB38	3.1	9.31	4.17	1.83	1.38	4.56	PRTB39
1-1/4"	PRHTB448	5.2	11.00	4.38	2.27	1.75	5.31	-
1-1/2"	PRHTB58	7.0	13.38	5.07	2.83	2.13	6.50	-
2"	PRHTB68	11.0	16.25	5.85	3.83	3.00	8.56	-

TB FORM 7

Pipe Size	FERROUS CATALOG #	Nominal Weight	A	B	C	D	E	ALUMINUM CATALOG #
1/2"	PRTB17	1.6	6.63	2.67	1.64	0.94	3.19	PRTB19
3/4"	PRTB27	2.1	7.75	2.92	1.83	1.13	3.81	PRTB29
1"	PRTB37	2.7	9.25	3.29	2.08	1.38	4.50	PRTB39
1-1/4"	PRTB47	3.7	9.94	3.35	2.27	1.75	5.00	-
1-1/2"	PRTB57	4.7	11.19	5.04	2.52	1.94	5.44	-
2"	PRTB67	7.0	13.19	6.17	3.08	2.44	6.38	-