

# PLASTI-BOND REDH<sub>2</sub>O<sub>T</sub> REDUCING AND SPLIT COUPLINGS

## REDUCING AND SPLIT COUPLINGS

### Reducing Couplings Specifications

#### APPLICATION

PLASTI-BOND REDH<sub>2</sub>O<sub>T</sub> reducing couplings are used to connect two pieces of conduit of different size. They are available in 17 different size combinations.

#### FEATURES

- 40 mil gray PVC exterior coating
- 2 mil red urethane interior coating
- 17 trade sizes from 1/2" through 4".
- Sealing sleeves on all conduit openings

#### COMPLIANCES

- National Electric Code/CEC Class I, Division 1 & 2, Groups A, B, C, D Class II, Division 2, Groups F, G
- UL Standard 886
- CSA Standard: C22.2 No. 18



PRREC32

### REDUCING COUPLINGS

Pipe Size	FERROUS Catalog #	Nominal Weight	Aluminum Catalog #
3/4" – 1/2"	PRREC21	0.2	PRREC21SA
1" – 1/2"	PRREC31	0.7	PRREC31SA
1" – 3/4"	PRREC32	0.5	PRREC32SA
1-1/4" – 3/4"	PRREC42	1.0	PRREC42SA
1-1/4" – 1"	PRREC43	0.8	PRREC43SA
1-1/2" – 3/4"	PRREC52	1.4	PRREC52SA
1-1/2" – 1"	PRREC53	1.2	PRREC53SA
1-1/2" – 1-1/4"	PRREC54	1.3	PRREC54SA
2" – 3/4"	PRREC602	1.5	PRREC602SA
2" – 1"	PRREC603	2.3	PRREC603SA
2" – 1-1/4"	PRREC604	2.6	PRREC604SA
2" – 1-1/2"	PRREC605	2.8	PRREC605SA
2-1/2" – 1-1/2"	PRREC75	3.2	–
3" – 2"	PRREC86	3.7	PRREC86SA
3-1/2" – 2-1/2"	PRREC97	4.6	–
4" – 3"	PRREC108	5.9	–
5" – 4"	PRREC01210	7.4	–

### Split Couplings Specifications

#### APPLICATION


PLASTI-BOND REDH<sub>2</sub>O<sub>T</sub> split couplings are used to connect two pieces of conduit where the conduit can't be turned because of limited clearance between runs or a wall or other obstruction.

#### FEATURES

- 40 mil gray PVC exterior coating
- 2 mil red urethane interior coating
- 12 trade sizes from 1/2" through 6".
- Sealing sleeves on all conduit openings

#### COMPLIANCES

- UL Standard 514B
- CSA Standard: C22.2 No. 18

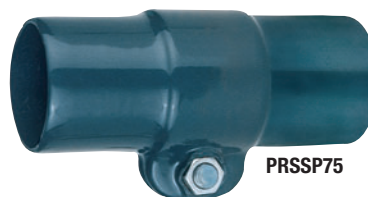

PRSSP75

### SPLIT COUPLINGS

Pipe Size	FERROUS Catalog #	Nominal Weight
1/2"	PRSSP50	0.2
3/4"	PRSSP75	0.3
1"	PRSSP100	0.4
1-1/4"	PRSSP125	0.6
1-1/2"	PRSSP150	0.7
2"	PRSSP200	1.0
2-1/2"	PRSSP250	2.3
3"	PRSSP300	3.0
3-1/2"	PRSSP350	3.8
4"	PRSSP400	4.1
5"	PRSSP500	6.0
6"	PRSSP600	8.6

#### APPROVAL STAMP

(See online product submittal guide at [www.plastibond.com](http://www.plastibond.com))