


TYPE "PLH" CUTOUT PORCELAIN

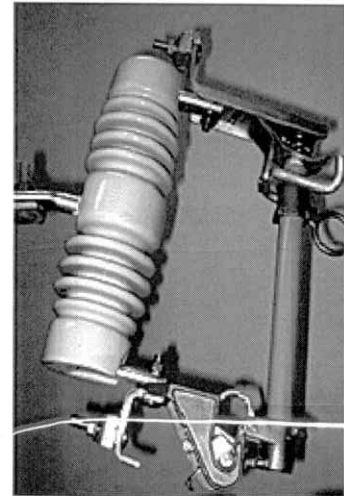

CUT OUT

15 KV (95 / 100 BIL)

Catalog #	Maximum Voltage	Continuous Current (amps) (Asym)	Interrupt Capacity	Arc Short Rod	BIL	Leakage Distance	Weight (Each)
PLH-115-195PN	15 KV	100	10,000	NO	95 KV	8 1/2"/216mm	18 lbs
PLH-115-295PN	15 KV	100	16,000	YES	95 KV	8 1/2"/216mm	18 lbs
PLH-215-395PN	15 KV	200	12,000	YES	95 KV	8 1/2"/216mm	20 lbs

27KV (125 BIL)

Catalog #	Maximum Voltage	Continuous Current (amps) (Asym)	Interrupt Capacity	Arc Short Rod	BIL	Leakage Distance	Weight (Each)
PLH-127-1125PN	27 KV	100	8,000	NO	125 KV	11"/279mm	20 lbs
PLH-127-2125PN	27 KV	100	12,000	YES	125 KV	11"/279mm	20 lbs
PLH-227-3125PN	27 KV	200	10,000	YES	125 KV	11"/279mm	20 lbs

27KV (150 BIL)

Catalog #	Maximum Voltage	Continuous Current (amps) (Asym)	Interrupt Capacity	Arc Short Rod	BIL	Leakage Distance	Weight (Each)
PLH-127-1150PN	27 KV	100	8,000	NO	150 KV	17"/432mm	26 lbs
PLH-127-2150PN	27 KV	100	12,000	YES	150 KV	17"/432mm	26 lbs
PLH-227-3150PN	27 KV	200	10,000	YES	150 KV	17"/432mm	26 lbs

P = Parallel groove clamp

N = Nema Bracket

To order a small eyebolt connector (no 8 solid thru 2/0 stranded), change P to E

Example : PLH-115-195EN

To order without Nema bracket, drop the "N" **Example : PLH-115-195P**

To order an extended Nema bracket, add X to ending of part number

Example : PLH-115-195PNX

PLH fuse holders are interchangeable with S & C, Chance, Cooper and ABB



POWERLINE HARDWARE

6841 Phillips Parkway Drive S, Jacksonville, Florida 32256

Phone: 904-288-9880, Fax: 904-268-9717

E-mail : sales@powerlinehardware.com