


Type _____
 -09 -20 -30
 P2642

Catalog No.	Finish			Dimensions (Inches)	
	Brushed Nickel	Antique Bronze	White	A	B
P2642	-09	-20	-30	13-5/8"	7"

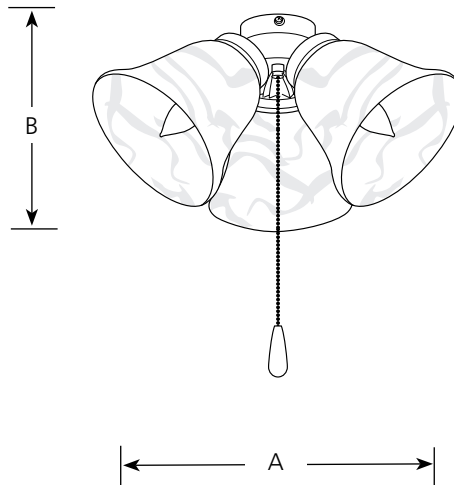

Specifications:

General

- Three alabaster glass shades
- 5-3/8" dia. x 4-7/8" ht., 1-5/8" dia. center hole
- Pull chain on Brushed Nickel (-09) is chrome with a maple fob, White (-30) finish is chrome with a white fob, and Antique Bronze (-20) is antique brass with a medium oak fob.
- Utilizes (3) 60-watt candelabra based lamps, included.
- Brushed Nickel (-09) is a plated finish
- Steel construction

Mounting

- Universal -use with any indoor fan with 1/8" IPS light kit adapter

Electrical

- Three ceramic candelabra based sockets
- Quick connect wiring to fan
- Prewired
- 190-watt limiter

Labeling

- UL listed