

PS4-11-15D2

Square steel poles drilled for 2 Area Lights at 180°. Designed for ground mounting. Poles are stocked nationwide for quick shipment. Protective packaging ensures poles arrive at the job site good as new.

Color: Bronze

Weight: 106.0 lbs

Lamp Info

Type: N/A
 Watts: 0W
 Shape/Size: N/A
 Base: N/A
 ANSI: N/A
 Hours: 0
 Lamp Lumens: 0
 Efficacy: N/A

Ballast Info

Type: N/A
 120V: N/A
 208V: N/A
 240V: N/A
 277V: N/A
 Input Watts: 0W
 Efficiency: N/A

Technical Specifications

CSA Listed:

Suitable for wet locations

Shaft:

46,000 p.s.i. minimum yield

Hand Holes:

Reinforced with grounding lug and removable cover.

Base Plates:

Slotted base plates 36,000 p.s.i.

Shipping Protection:

All poles are shipped in individual corrugated cartons to prevent finish damage.

Color:

Bronze powder coating

Terms of Sale:

Pole Terms of Sale is available

Height:

15 FT

Weight:

106 lbs.

Gauge:

11

Wall Thickness:


1/8"

Shaft Size:

4"

Hand Hole Dimensions:

3" x 5"

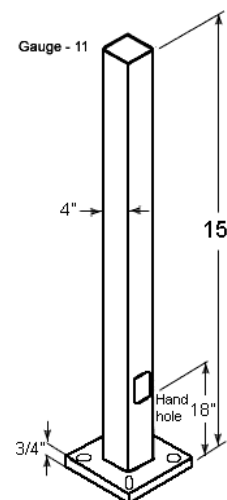

Bolt Circle:

8-9"

Base Dimension:

8"

Anchor Bolt:

Galvanized anchor bolts and galvanized hardware and anchor bolt template. All bolts have a 3" hook

Anchor Bolt Templates:

WARNING Template must be printed on 11" x 17" sheet for actual size. CHECK SCALE BEFORE USING. Templates shipped with anchor bolts and available

Pre-Shipped Anchor Bolts:

Bolts can be pre-shipped upon request for additional freight charge

MaxEPA's/Max Weights:

70MPH 14.0 ft_/400 lb
 80MPH 10.2 ft_/295 lb
 90MPH 7.6 ft_/220 lb
 100MPH 5.6 ft_/165 lb
 110MPH 4.2 ft_/125 lb
 120MPH 3.0 ft_/95 lb
 130MPH 2.1 ft_/70 lb
 140MPH 1.4 ft_/50 lb
 150MPH 0.8 ft_/35 lb