

RB6T5



RAB offers energy efficient fluorescent fixtures for large space lighting including warehouses, factories, and distribution centers. The RBAY delivers the high quality needed for these applications with strong, heavy duty 22 gauge rigid housing with no sharp edges. The superior strong-box protective foam case packaging protects the RBAY so it arrives in perfect shape and ready to install.

Color: N/A

Weight: 21.0 lbs

Project:

Type:

Prepared By:

Date:

Lamp Info

Type: T5HO
Watts: 324W
Shape/Size: N/A
Base: N/A
ANSI: N/A
Hours: 20,000
Lamp Lumens: 24008
Efficacy: 66 LPW

Ballast Info

Type: Prog. Start
120V: 3.00A
208V: 1.77A
240V: 1.54A
277V: 1.33A
Input Watts: 362W
Efficiency: 90%

Technical Specifications

Listings

UL Listing:

Dry Locations Only. Ceiling Mount Only.

Construction

Housing:

Heavy duty 22 gauge steel housing and wiring box with 1/2" NPS knockouts. Painted white. Easy wiring and maintenance access panel. Includes "Y" hooks.

Reflector:

Aluminum High Performance brilliant bevel segmented reflectors.

Base:

Medium Bi Pin.

Reflector:

Alanoed 320G-E with reflectivity of ≥86%.

Optical

Lamp:

T5HO (not supplied).

Other

CRI:

85

Mounts:

Surface or Chain (Y Hooks included).

Electrical

Total Watts:

6x54W.

Input Volts:

120-277V.


Input Amps:

3.0/1.28.

Ballast Factor:

1.00.

Dimensions

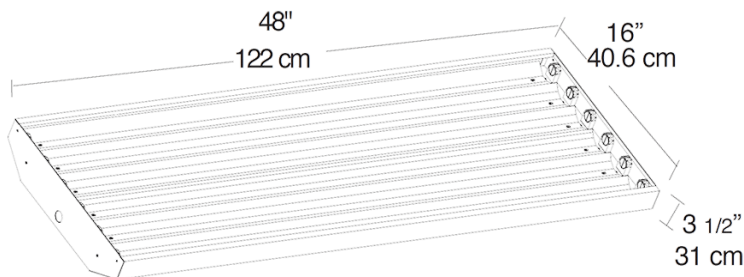

Features

- Qualifies for EPA Act 2005 incentives
- Post-painted, high reflective gloss white powder coat finish
- High Performance, brilliant bevel segmented reflectors
- Easy wiring and maintenance access panel
- Rotary locking lamp holders for vibration security and easy relamping
- Heavy duty 22 gauge steel Rigid strong housing with no sharp edges