

## SPECIFICATIONS



US METRIC

<b>OVERALL LENGTH</b>	6.21"	<b>CLOSED LENGTH</b>	3.85"
<b>PRODUCT WEIGHT</b>	2.80 OZ	<b>BLADE LENGTH</b>	2.85"
<b>BLADE THICKNESS</b>	0.1"	<b>UPC</b>	7 29057 99456 2
<b>PRODUCT FAMILY</b>	TWITCH II	<b>PRODUCT TYPE</b>	FOLDING KNIFE
<b>LOCKING MECHANISM</b>	LOCKBACK	<b>OPENING MECHANISM</b>	ASSISTED
<b>BELT CLIP TYPE</b>	FIXED	<b>PACKAGING</b>	UNIBOX - DISPLAY READY
<b>ENGRAVABLE</b>	YES	<b>FINISH</b>	SATIN
<b>EDGE TYPE</b>	STRAIGHT	<b>BLADE STEEL TYPE</b>	AUS-8
<b>BLADE SHAPE</b>	DRIP POINT	<b>HARDNESS</b>	HRC 57/58
<b>HANDLE MATERIAL</b>	ANODIZED ALUMINUM 6061T6	<b>HANDLE COLOR</b>	GRAPHITE

## DESCRIPTION

Engineered with SOG Assisted Technology (S.A.T.™), the Twitch is extremely quick to open with either hand using the double thumb studs or kink on the back. Its full metal construction is durable and sturdy. The clip can be used for law carry or securing dollar bills and cards. Incorporating into the design is a visible safety lock that helps insures the blade will not open while being carried on those unexpectedly while in use. The SOG Twitch series is a great EDC with a variety of options to choose from.

### BLADE DETAILS

#### BLADE SHAPE [ DROP POINT ]

Great all around blade shape, good for most outdoor and hunting tasks.

#### BLADE STEEL TYPE [ AUS-8 ]

High grade stainless steel with excellent edge retention and rust resistance.

### HANDLE DETAILS


#### HANDLE MATERIAL [ ANODIZED ALUMINUM

#### 6061-T6 ]

Machined aluminum with a hard-anodized coating. Lightweight and durable.

#### HANDLE COLOR [ GRAPHITE ]

## TECHNOLOGIES

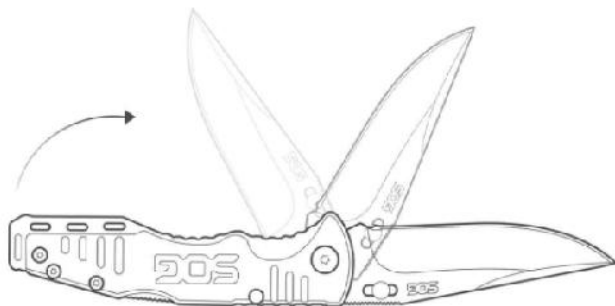

### SOG ASSISTED TECHNOLOGY™

SOG Assisted Technology (S.A.T.) works through the balance of opposing high-tension coil springs. As you initiate the opening action, the force propelling your blade open becomes greater than the force keeping it closed. The result is a blade that springs open instantly once it is engaged, seemingly on its own.