

# Neon Glow Lamps

Line No.	Lamp No.	Bulb Type	Base	Circuit Volts	Breakdown Voltage		Watts	Series Resistance (OHMS)	Life Hours	Fig. No.
					AC	Max DC				
1	A1A	T-2	Wire Terminal	105-125	65	90	1/17	150,000	25K	51
2	A1B	T-2	Wire Terminal	105-125	65	90	1/25	220,000	25K	51
3	A9A	T-2	Wire Terminal	105-125	65	90	1/15	100,000	25K	51
4	B1A	T-3 1/4	Miniature Bayonet	105-125	95	135	1/25	220,000	15K	52
5	B2A	T-3 1/4	Miniature Bayonet	105-125	95	135	1/7	47,000	25K	52
6	B7A	T-4 1/2	Candelabra	105-125	65	90	1/4	30,000	5K	53
7	B9A	T-4 1/2	D.C. Bayonet	105-125	65	90	1/4	30,000	5K	54
8	C2A	T-2	Wire Terminal	105-125	95	135	1/4	30,000	25K	51
9	C7A	T-2	S.C. Midget Flange	105-125	65	90	1/15	100,000	25K	55
10	C9A	T-2	S.C. Midget Flange	105-125	95	135	1/4	30,000	25K	55

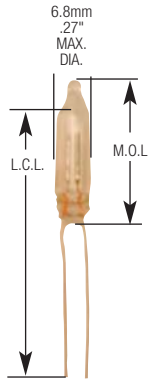


Fig. 51

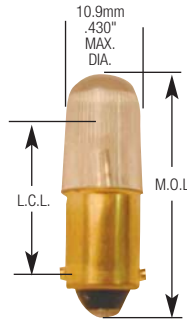


Fig. 52

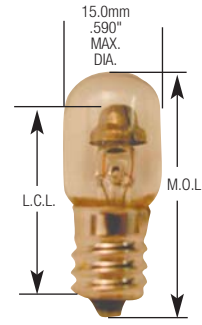


Fig. 53

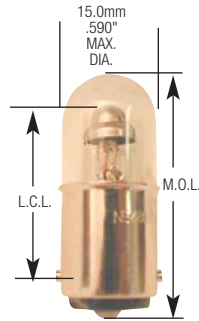


Fig. 54

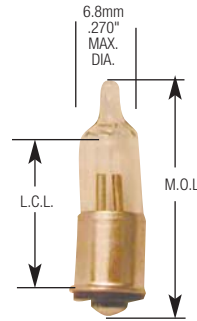


Fig. 55

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK  
 PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED  
 949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141