

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
B-3 1/2 Bulb											
1	PR4	S.C. Miniature Flanged	2.33	.27	.40	C-2R	1.25	.25	10	Flashlight-2 C Cells	1
2	PR2	S.C. Miniature Flanged	2.38	.50	.80	C-2R	1.25	.25	15	Flashlight-2 D Cells	1
3	K2	S.C. Miniature Flanged	2.4	.70	1.20	C-2R	1.25	.25	15	Flashlight-Krypton 2 Cells	1
4	KPR102	S.C. Miniature Flanged	2.4	.70	1.30	C-2R	1.25	.25	15	Flashlight-Krypton 2 Cells	1
5	PR6	S.C. Miniature Flanged	2.47	.30	.45	C-2R	1.25	.25	30	Flashlight-2 D Cells	1
6	PR3	S.C. Miniature Flanged	3.57	.50	1.5	C-2R	1.25	.25	15	Flashlight-3 D Cells	1
7	K3	S.C. Miniature Flanged	3.6	.90	3.4	C-2R	1.25	.25	15	Flashlight-Krypton 3 Cells	1
8	KPR103	S.C. Miniature Flanged	3.6	.75	2.7	C-2R	1.25	.25	20	Flashlight-Krypton 3 Cells	1
9	PR7	S.C. Miniature Flanged	3.7	.30	.90	C-2R	1.25	.25	30	Flashlight-3 Cells	1
10	PR30	S.C. Miniature Flanged	3.75	.86	2.25	C-2R	1.25	.25	40	Flashlight-3 Cells	1
11	PR13	S.C. Miniature Flanged	4.75	.50	2.0	C-2R	1.25	.25	15	Flashlight-4 F Cells	1
12	K13	S.C. Miniature Flanged	4.75	.70	4.0	C-2R	1.25	.25	15	Flashlight-Krypton 4 Cells	1
13	KPR113	S.C. Miniature Flanged	4.8	.75	4.06	C-2R	1.25	.25	20	Flashlight-Krypton 4 Cells	1
14	PR15	S.C. Miniature Flanged	4.82	.50	2.0	C-2R	1.25	.25	30	Hand Lantern-8 F Cells	1
15	PR17	S.C. Miniature Flanged	4.9	.30	1.2	C-2R	1.25	.25	30	Hand Lantern-8 F Cells	1
16	K12	S.C. Miniature Flanged	5.95	.70	7.5	C-2R	1.25	.25	8	Hand Lantern-Krypton 8 F Cells	1
17	PR12	S.C. Miniature Flanged	5.95	.50	3.0	C-2R	1.25	.25	15	Flashlight-5 D Cells	1
18	PR18	S.C. Miniature Flanged	7.2	.55	4.2	C-2R	1.25	.25	3	Flashlight-6 D Cells	1
19	PR20	S.C. Miniature Flanged	8.63	.50	5.0	C-2R	1.25	.25	15	Flashlight-7 D Cells	1
20	PR16	S.C. Miniature Flanged	12.5	.25	2.7	C-2R	1.25	.25	50	Auto Spotlight	1
B-6 Bulb											
21	210	D.C. Bayonet	6.5	1.78	15	C-6	1.75	1.06	100	Instrument	3
22	1003	S.C. Bayonet	12.8	.94	15	C-6	1.75	1.06	100	Auto Interior	2
23	1004	D.C. Bayonet	12.8	.94	15	C-6	1.75	1.06	100	Auto Interior	3
24	104	D.C. Bayonet	12.8	1.0	12	C-6	1.75	1.06	500	Auto Interior	3
25	105	S.C. Bayonet	12.8	1.0	12	C-6	1.75	1.06	500	Auto Interior	2
26	1309	S.C. Bayonet	28.0	.52	15	2C-2R	1.75	1.06	300	Aircraft Interior	2
27	1308	S.C. Bayonet	28.0	.56	16	CC-8	1.75	1.06	2,000	Aircraft Interior	2

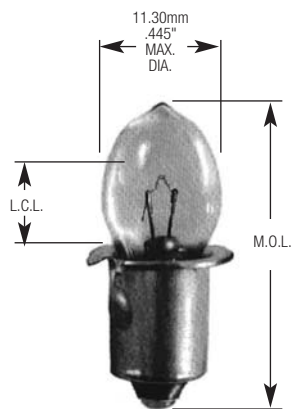


Fig. 1 (C-2R filament shown)

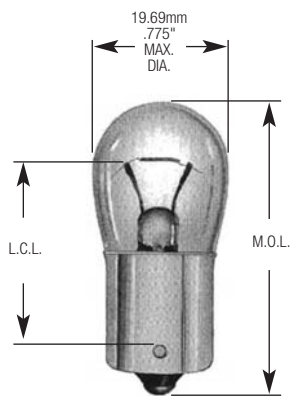


Fig. 2 (C-6 filament shown)

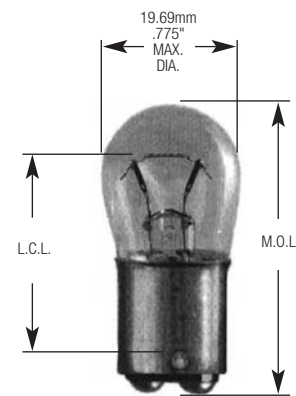


Fig. 3 (C-6 filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
G-3 1/2 Bulb											
1	131	Miniature Screw	1.3	.10	.03	S-2	.94	.72	50	Bicycle	4
2	233	Miniature Screw	2.33	.27	.42	C-2R	.94	.72	10	Flashlight-3 C Cells	4
3	245	Miniature Screw	2.46	.50	.90	C-2R	.94	.72	15	Flashlight-2 D Cells	4
4	10	Miniature Two Pin	2.5	.50	.50	C-6	.94	.63	3,000	Indicator	5
5	14	Miniature Screw	2.47	.30	.50	C-2R	.94	.72	15	Flashlight-2 D Cells	4
6	13	Miniature Screw	3.7	.30	.98	C-2R	.94	.72	15	Flashlight-3D Cells	4
7	12	Miniature Two Pin	6.3	.15	.35	C-6	.94	.63	5,000	Radio	5
8	51	Miniature Bayonet	7.5	.22	1.0	C-2R	.94	.50	1,000	Indicator	6
9	1446	Miniature Screw	12.0	.20	1.7	C-2R	.94	.72	250	Toy Train	4
10	1449	Miniature Screw	14.0	.20	2.0	C-2V	.94	.72	250	Toy Train	4
11	19	Miniature Two Pin	14.4	.10	.90	C-6	.94	.63	1,000	Toy Train	5
12	53	Miniature Bayonet	14.4	.12	1.0	C-2V	.94	.50	1,000	Auto	6
13	1445	Miniature Bayonet	14.4	.13	.70	C-2F	.94	.50	2,000	Auto	6
14	1450	Miniature Bayonet	24.0	.035	.23	C-2F	.94	.50	3,000	Indicator	6
15	265	Miniature Bayonet	28.0	.08	.75	C-2F	.94	.50	5,000	Indicator	6
16	356	Miniature Bayonet	28.0	.17	3.5	C-2F	.94	.50	500	Aircraft	6

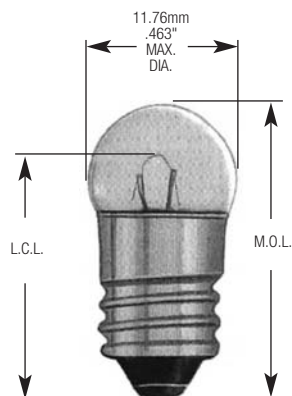


Fig. 4 (C-2V filament shown)

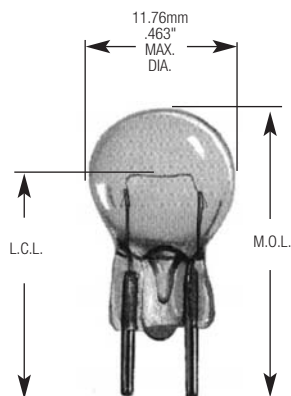


Fig. 5 (C-6 filament shown)

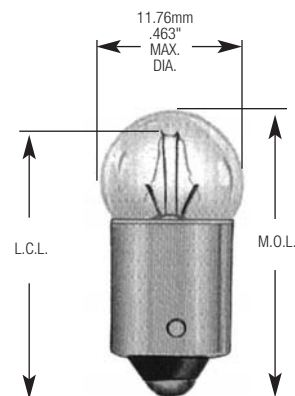


Fig. 6 (C-2F filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
G-4 1/2 Bulb											
1	27	Miniature Screw	4.9	.30	1.4	C-2R	1.063	.72	30	Lantern-4 F Cells	7
2	407	Miniature Screw	4.9	.30	-	C-2R	1.06	.81	50	Hand Lantern	7
3	425	Miniature Screw	5.0	.50	2.3	C-2R	1.06	.72	15	Hand Lantern-4 F Cells	7
4	502	Miniature Screw	5.1	.15	.60	C-2R	1.06	.72	100	Hand Lantern-4 F Cells	7
5	503	Miniature Bayonet	5.1	.15	.60	C-2R	1.07	.56	100	Lantern	8
6	605	Miniature Screw	6.1	.50	3.4	C-2R	1.07	.72	15	Flashlight	7
7	455	Miniature Bayonet	6.5	.50	1.9	C-2R	1.06	.56	500	Indicator	8
8	15	Miniature Two Pin	7.0	.40	2.0	C-6	1.07	.69	500	Indicator	9
9	55	Miniature Bayonet	7.0	.41	2.0	C-2R	1.06	.56	500	Auto Instrument	8
10	428	Miniature Screw	12.5	.25	2.4	C-2V	1.06	.72	250	Toy Train	7
11	57	Miniature Bayonet	14.0	.24	2.0	C-2V	1.06	.56	500	Auto Instrument	8
12	257	Miniature Bayonet	14.0	.27	-	C-2R	1.06	.63	500	Auto	8
13	258	Miniature Screw	14.0	.27	1.6	C-2R	1.07	.81	500	Toy Train, Flasher	7
14	1895	Miniature Bayonet	14.0	.27	2.0	C-2F	1.06	.56	2,000	Auto	8
15	1895B	Miniature Bayonet	14.0	.27	-	C-2F	1.06	-	2,000	Auto	8
16	1895R	Miniature Bayonet	14.0	.27	-	C-2F	1.06	-	2,000	Auto	8
17	293	Miniature Bayonet	14.0	.33	2.0	C-2F	1.06	.56	5,000	Auto	8
18	456	Miniature Bayonet	28.0	.17	2.0	C-2F	1.07	.56	5,000	Instrument	8

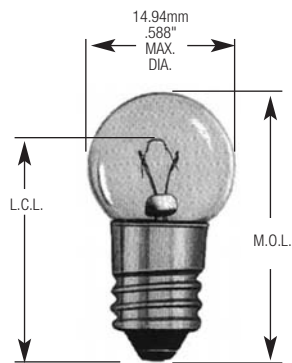


Fig. 7 (C-2R filament shown)

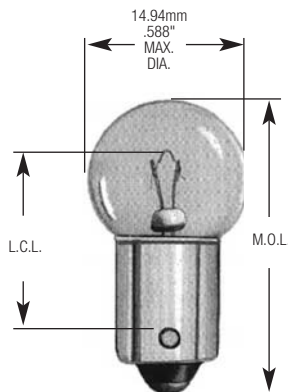


Fig. 8 (C-2R filament shown)

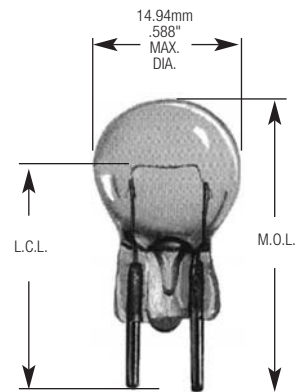


Fig. 9 (C-6 filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
G-6 Bulb											
1	157	Miniature Screw	5.8	1.1	8.1	C-2R	1.44	1.0	50	Medical	10
2	81	S.C. Bayonet	6.5	1.02	6	C-2R	1.44	.75	500	Auto	11
3	82	D.C. Bayonet	6.5	1.02	6	C-2R	1.44	.75	500	Auto	12
4	63	S.C. Bayonet	7.0	.63	3	C-2R	1.44	.75	1,000	Auto	11
5	64	D.C. Bayonet	7.0	.63	3	C-2R	1.44	.75	1,000	Auto	12
6	89	S.C. Bayonet	13.0	.58	6	C-2R	1.44	.75	750	Auto	11
7	90	D.C. Bayonet	13.0	.58	6	C-2R	1.44	.75	750	Auto	12
8	98	D.C. Bayonet	13.0	.62	6	C-2V	1.44	.75	800	Auto	12
9	99	D.C. Bayonet	13.0	.62	6	C-2V	1.44	.75	800	Auto	12
10	67	S.C. Bayonet	13.5	.59	4	C-2R	1.44	.81	5,000	Auto	11
11	68	D.C. Bayonet	13.5	.59	4	C-2R	1.44	.83	5,000	Auto	12
12	1155	S.C. Bayonet	13.5	.59	4	2C-2R	1.44	.83	5,000	Auto	11
13	97	S.C. Bayonet	13.5	.69	4	C-2V	1.44	.81	5,000	Auto	11
14	1178	D.C. Bayonet	13.5	.69	4	C-2V	1.44	.81	5,000	Auto	12
15	631	S.C. Bayonet	14.0	.63	6	2C-6	1.44	.72	1,000	Auto	11
16	509K	Candelabra Screw	24.0	.18	2.8	C-2F	1.38	.94	1,000	Indicator	-
17	1251	S.C. Bayonet	28.0	.23	3	2C-6	1.44	.75	2,000	Auto	11
18	1252	D.C. Bayonet	28.0	.23	3	2C-6	1.44	.75	2,000	Auto	12
19	303	S.C. Bayonet	28.0	.30	6	C-2F	1.44	.75	500	Aircraft	11
20	304	D.C. Bayonet	28.0	.30	6	C-2F	1.44	.75	500	Aircraft	12
21	623	S.C. Bayonet	28.0	.37	6	2C-6	1.44	.75	1,000	Auto	11
22	624	D.C. Bayonet	28.0	.37	6	2C-6	1.44	.75	1,000	Auto	12
23	1224	D.C. Bayonet	32.0	.16	3.8	C-2F	1.44	.75	500	Marine	12

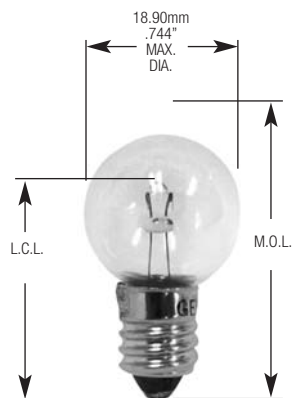


Fig. 10 (C-2R filament shown)

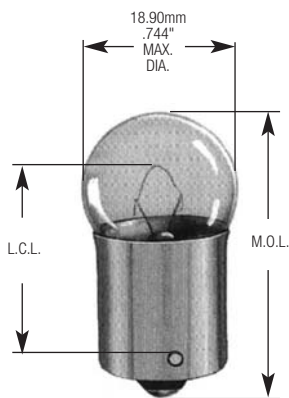


Fig. 11 (C-2R filament shown)

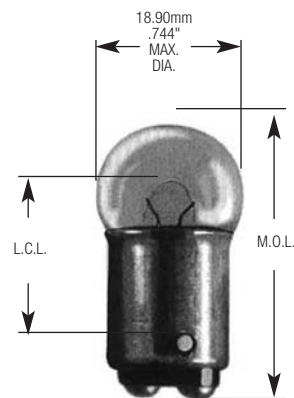


Fig. 12 (C-2R filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
RP-11 Bulb											
1	1183	S.C. Bayonet	5.5	6.25	50	C-2V	2.25	1.25	50	Auto	13
2	1184	D.C. Bayonet	5.5	6.25	50	C-2V	2.25	1.25	10	Auto	14
3	1133	S.C. Bayonet	6.2	3.91	32	C-2R	2.25	1.25	15	Instrument	13
4	1143IF	S.C. Bayonet	12.5	1.98	-	C-2R	2.25	1.25	15	Rec. Vehicle	13
5	1195	S.C. Bayonet	12.5	3.00	50	C-2V	2.25	1.25	15	Auto	13
6	1196	D.C. Bayonet	12.5	3.00	50	C-2V	2.25	1.25	5,000	Auto	14
7	1293	S.C. Bayonet	12.5	3.00	50	C-2R	2.25	1.25	1,000	Auto	13
8	1139IF	S.C. Bayonet	12.8	1.04	15	C-6	2.25	1.25	250	Rec. Vehicle	13
9	1047	S.C. Bayonet	26.0	2.7	105	2CC-6	2.25	1.25	250	Aircraft	13
10	1054	D.C. Bayonet	32.0	.74	32	C-2V	2.25	1.25	1,000	Marine	14
11	1062	D.C. Bayonet	40.0	.92	50	C-5	2.25	1.25	500	Special Service	14
R-12 Bulb											
12	1383	S.C. Bayonet	13.0	1.50	-	C-8	2.63	-	300	Auto Reading	15
13	1385	S.C. Bayonet	28.0	.72	-	CC-8	2.63	-	300	Aircraft Reading	15
S-8 Bulb											
14	1651	S.C. Bayonet	5.0	.60	3	C-2R	2.00	1.13	20	Lantern-4 F Cells	16
15	1612	D.C. Bayonet	5.4	1.9	10	C-6	2.00	1.25	1,000	Instrument	18
16	1680	S.C. Bayonet	6.0	4.10	32	C-6	2.00	1.25	300	Aircraft	16
17	1680X	S.C. Bayonet	6.0	4.10	32	C-6	2.00	1.25	300	Aircraft	16
18	1154	D.C. Index	6.3	2.63	21	C-6	2.00	1.25	200	Auto-Park, Tail, Signal	17
			7.0	.75	3	C-6			1,000		
19	1129	S.C. Bayonet	6.4	2.63	21	C-6	2.00	1.25	200	Auto	16
20	6	D.C. Bayonet	6.4	3.0	23	C-2R	2.00	1.25	500	Special Service	18
21	1460	D.C. Prefocus	6.5	2.75	23	C-6	2.00	1.25	100	Medical Instrument	19
22	1460X	D.C. Prefocus	6.5	2.75	23	C-6	2.00	1.25	100	Silver Contacts	19
23	1493	D.C. Bayonet	6.5	2.75	23	C-6	2.00	1.13	100	Instrument	18
24	1630	D.C. Prefocus	6.5	2.75	23	C-6	2.00	1.00	100	Instrument	19
25	1631X	D.C. Prefocus	6.5	2.75	23	C-6	2.00	1.00	100	Instrument Silver Contacts	19
26	1619	S.C. Bayonet	6.7	1.90	15	C-6	2.00	1.13	500	Instrument	16
27	88	D.C. Bayonet	6.8	1.9	15	C-6	2.00	1.13	300	Auto	18
28	1295	S.C. Bayonet	12.5	3.0	50	C-2R	2.00	1.25	300	Auto	16
29	1295NA	S.C. Bayonet	12.5	3.0	37	C-2R	2.00	1.25	300	Auto Signal	16
30	93	S.C. Bayonet	12.8	1.04	15	C-2R	2.00	1.13	700	Auto	16
31	94	D.C. Bayonet	12.8	1.04	15	C-2R	2.00	1.13	700	Auto	18

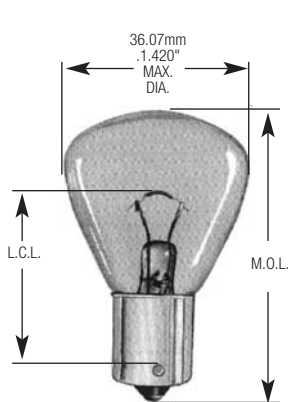


Fig. 13 (C-2R filament shown)

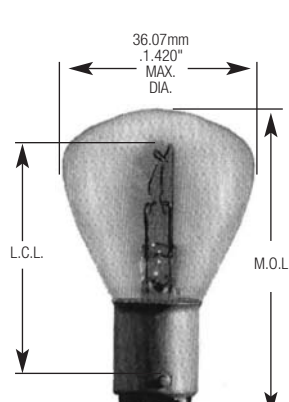


Fig. 14 (C-2V filament shown)



Fig. 15

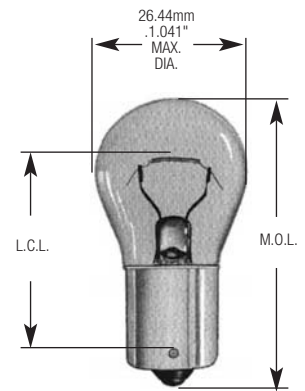


Fig. 16 (C-6 filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
S-8 Bulb (Continued)											
1	1016	D.C. Index	12.8	1.34	15	C-6	2.00	1.25	300	Auto-Park, Tail, Signal	17
			14.0	.59	21	C-6		1.25	1,000		
2	1152	D.C. Bayonet	12.8	1.34	21	C-2R	2.00	1.25	500	Auto	18
3	1176	D.C. Bayonet	12.8	1.34	21	C-6	2.00	1.25	200	Auto-Park, Tail, Signal	18
			14.0	.59	6	C-6			1,000		
4	1141	S.C. Bayonet	12.8	1.44	21	C-6	2.00	1.25	1,000	Auto	16
5	1141A	S.C. Bayonet	12.8	1.44	-	C-6	2.00	-	1,000	Auto	16
6	1141IF	S.C. Bayonet	12.8	1.44	-	C-6	2.00	-	1,000	Auto	16
7	1142	D.C. Bayonet	12.8	1.44	21	C-6	2.00	1.25	1,000	Auto	18
8	3155	S.F. Wedge	12.8	1.44	21	C-6	2.13	1.13	1,000	Auto	-
9	1034	D.C. Index	12.8	1.80	32	C-6	2.00	1.25	200	Auto-Park, Tail, Signal	17
			14.0	.59	3	C-6		-	5,000		
10	1034A	D.C. Index	12.8	1.8	-	C-6	2.00		200	Auto-Park, Tail, Signal	17
			14.0	.59	-	C-6			5,000		
11	1073	S.C. Bayonet	12.8	1.8	32	C-6	2.00	1.25	200	Auto Signal	16
12	1076	D.C. Bayonet	12.8	1.8	32	C-6	2.00	1.25	200	Auto	18
13	1076IF	D.C. Bayonet	12.8	1.8	-	C-6	2.00	1.25	200	Auto	18
14	1156	S.C. Bayonet	12.8	2.10	32	C-6	2.00	1.25	1,200	Auto	16
15	1156LL	S.C. Bayonet	12.8	2.10	32	C-6	2.00	1.25	2,400	Auto	16
16	1156DC	D.C. Bayonet	12.8	2.10	32	C-6	2.00	1.25	1,200	Auto	18
17	1156A	S.C. Bayonet	12.8	2.10	-	C-6	2.00	1.25	1,200	Auto	16
18	1156NA	S.C. Bayonet	12.8	2.10	24	C-6	2.00	1.25	1,200	Auto	16
19	1157	D.C. Index	12.8	2.10	32	C-6	2.00	1.25	1,200	Auto-Park, Tail, Signal	17
			14.0	.59	3	C-6		-	5,000		
20	1157LL	D.C. Index	12.8	2.10	32	C-6	2.00	1.25	2,400	Auto-Park, Tail, Signal	17
			14.0	.59	3	C-6		-	10,000		
21	1157A	D.C. Index	12.8	2.10	-	C-6	2.00	-	1,200	Auto-Park, Tail, Signal	17
			14.0	.59	-	C-6		-	5,000		
22	1157NA	D.C. Index	12.8	2.10	-	C-6	2.00	-	1,200	Auto-Park, Tail, Signal	17
			14.0	.59	-	C-6		-	5,000		

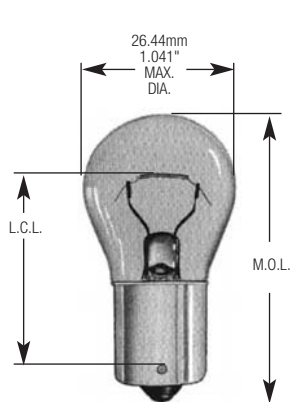


Fig. 16 (C-6 filament shown)

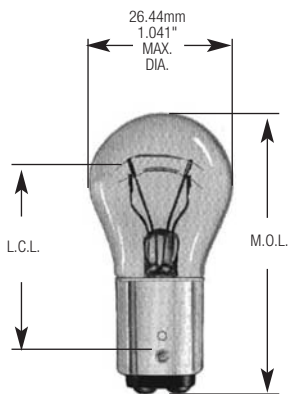


Fig. 17 (C-6/C-6 filament shown)

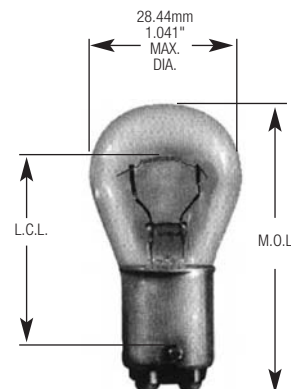


Fig. 18 (C-6 filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
 PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
 949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
S-8 Bulb (Continued)											
1	2057	D.C. Index	12.8 14.0	2.10 .48	32 2	C-6	2.00	1.25	1,200 5,000	Auto-Park, Tail, Signal	17
2	2057LL	D.C. Index	12.8 14.0	2.10 .48	32 2	C-6	2.00	1.25	2,400 10,000	Auto-Park, Tail, Signal	17
3	2057A	D.C. Index	12.8 14.0	2.10 .48	- -	C-6	2.00	1.25	1,200 5,000	Auto-Park, Tail, Signal	17
4	2057NA	D.C. Index	12.8 14.0	2.10 .48	24 1.5	C-6	2.00	1.25	1,200 5,000	Auto-Park, Tail, Signal	17
5	3057	D.F. Wedge	12.8 14.0	2.10 .48	32 2	C-6	2.13	1.13	1,200 5,000	Auto-Park, Tail, Signal	20
6	3057NA	D.F. Wedge	12.8 14.0	2.10 .48	24 1.5	C-6	2.13	1.13	1,200 5,000	Auto-Park, Tail, Signal	20
7	3156	S.F. Wedge	12.8	2.10	32	C-6	2.13	1.13	1,200	Auto	19
8	3157	D.F. Wedge	12.8 14.0	2.10 .59	32 3	C-6	2.13	1.13	1,200 5,000	Auto-Park, Tail, Signal	20
9	3157NA	D.F. Wedge	12.8 14.0	2.10 .59	24 2.2	C-6	2.13	1.13	1,200 5,000	Auto-Park, Tail, Signal	20
10	2357	D.C. Index	12.8 14.0	2.23 .59	40 3	C-6	2.00	1.25	400 5,000	Auto-Park, Tail, Signal	17
11	2357A	D.C. Index	12.8 14.0	2.20 .59	30 2.2	C-6	2.00	1.25	400 5,000	Auto-Park, Tail, Signal	17
12	2357NA	D.C. Index	12.8 14.0	1.8 .59	30 2.2	C-6	2.00	1.25	400 5,000	Auto-Park, Tail, Signal	17
13	3357	D.F. Wedge	12.8 14.0	2.23 .59	40 3	C-6	2.09	1.10	400 5,000	Auto-Park, Tail, Signal	20
14	3357NA	D.F. Wedge	12.8 14.0	2.23 .59	30 2.2	C-6	2.09	1.10	400 5,000	Auto-Park, Tail, Signal	20
15	198	D.C. Index	12.8 14.0	2.25 .62	32 3	C-6	2.00	1.25	1,200 5,000	Auto-Park, Tail, Signal	17
16	199	S.C. Bayonet	12.8	2.25	32	C-6	2.00	1.25	2400	Auto	16
17	1662	D.C. Index	28.0	.93 .34	32 6	CC-6	2.00	1.25	400 1,000	Construction Equipment	17

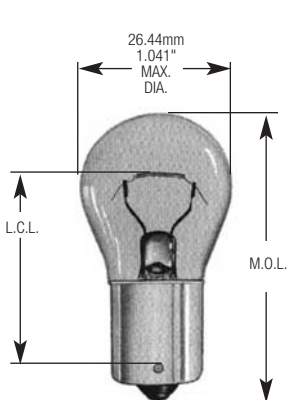


Fig. 16 (C-6 filament shown)

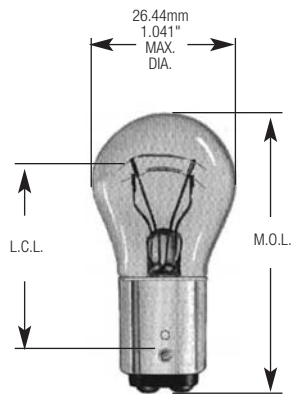


Fig. 17 (C-6/C-6 filament shown)

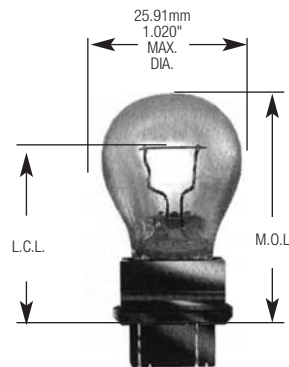


Fig. 20 (C-6/ filament shown)

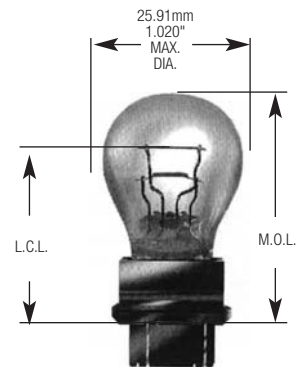


Fig. 20 (C-6/C-6 filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
S-8 Bulb (Continued)											
1	305	S.C. Bayonet	28.0	.51	15	C-2V	2.00	1.12	300	Aircraft	16
2	305IF	S.C. Bayonet	28.0	.51	-	C-2V	2.00	1.12	300	Aircraft, Inside Frost	16
3	306	D.C. Bayonet	28.0	.51	15	C-2V	2.00	1.12	300	Aircraft	18
4	306IF	D.C. Bayonet	28.0	.51	-	C-2V	2.00	1.12	300	Aircraft, Inside Frost	18
5	1591	S.C. Bayonet	28.0	.61	15	C-2V	2.00	1.12	1,000	Auto	16
6	1591IF	S.C. Bayonet	28.0	.61	-	C-2V	2.00	1.12	1,000	Auto, Inside Frost	16
7	1691	S.C. Bayonet	28.0	.61	15	2C-2R	2.00	1.12	1,000	Auto	16
8	1691IF	S.C. Bayonet	28.0	.61	-	2C-2R	2.00	1.12	1,000	Auto, Inside Frost	16
9	1692	D.C. Bayonet	28.0	.61	15	2C-2R	2.00	1.12	1,000	Marine	18
10	307	S.C. Bayonet	28.0	.67	21	C-2V	2.00	1.12	300	Aircraft	16
11	307IF	S.C. Bayonet	28.0	.67	-	C-2V	2.00	1.12	300	Aircraft, Inside Frost	16
12	307R	S.C. Bayonet	28.0	.67	-	C-2V	2.00	1.12	300	Aircraft, Red	16
13	308	D.C. Bayonet	28.0	.67	21	C-2V	2.00	1.12	300	Aircraft	18
14	308IF	D.C. Bayonet	28.0	.67	-	C-2V	2.00	1.12	300	Aircraft, Inside Frost	18
15	1203	S.C. Bayonet	28.0	.71	21	C-2V	2.00	1.25	400	Auto	16
16	1204	D.C. Bayonet	28.0	.71	21	C-2V	2.00	1.25	400	Auto	18
17	1665	S.C. Bayonet	28.0	.80	21	C-2V	2.00	1.12	1,000	Aircraft	16
18	1665IF	S.C. Bayonet	28.0	.80	-	C-2V	2.00	1.12	1,000	Aircraft, Inside Frost	16
19	1638	D.C. Bayonet	28.0	1.02	32	2C-6	2.00	1.25	500	Marine	18
20	1683	S.C. Bayonet	28.0	1.02	32	2C-6	2.00	1.25	500	Auto	16
21	1229	D.C. Bayonet	40.0	.38	15	C-2V	2.00	1.12	400	Special Service	18
22	895	D.C. Bayonet	40.0	.53	14	C-13	2.00	1.25	3,800	Railroad	18
S-11 Bulb											
23	309	S.C. Bayonet	28.0	.90	32	C-2V	2.38	1.25	300	Aircraft	21
24	311	S.C. Bayonet	28.0	1.29	50	C-2V	2.38	1.25	300	Aircraft	21
25	312	D.C. Bayonet	28.0	1.29	50	C-2V	2.38	1.25	300	Aircraft	22
26	3011	S.C. Bayonet	28.0	1.29	44	C-2V	2.38	1.25	1,000	Aircraft	21

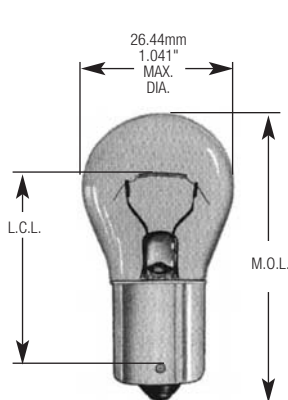


Fig. 16 (C-6 filament shown)

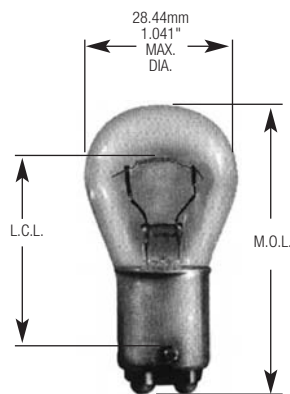


Fig. 18 (C-6 filament shown)

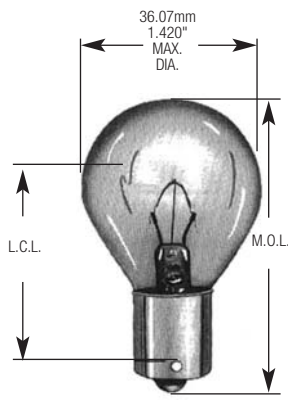


Fig. 21 (C-2V filament shown)

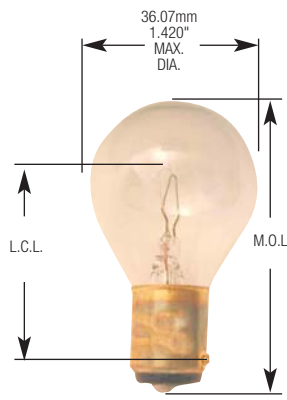


Fig. 22 (C-2V filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141