



**Presented By:** Depot Lighting  
Contact Phone: 888.763.6518  
Contact E-mail:

Customer Name:  
Project Name:  
Fixture Type:



GE  
Lighting

**35327 - 150PAR46/TS**  
GE PAR46 - Traffic Signal

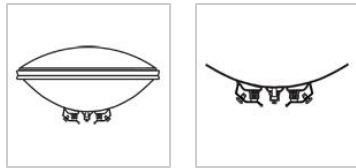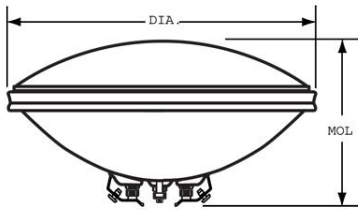

### GENERAL CHARACTERISTICS

Lamp Type	Sealed Beam - PAR
Bulb	PAR46
Base	3 Prong
Filament	CC-6
Wattage	150
Voltage	115
Rated Life	6000 hrs
Primary Application	Traffic Signal

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1750
Nominal Initial Lumens per Watt	11

### ELECTRICAL CHARACTERISTICS

Burn Position	Horizontal
---------------	------------

### DIMENSIONS

Maximum Overall Length (MOL)	4.0000 in(101.6 mm)
Bulb Diameter (DIA)	5.750 in(146.0 mm)
Bulb Diameter (DIA) (MAX)	5.750 in(146.0 mm)

### PRODUCT INFORMATION

Product Code	35327
Description	150PAR46/TS
Standard Package	Case
Standard Package GTIN	10043168353271
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168353274

### CAUTIONS & WARNINGS

#### Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
  - Use in enclosed fixture rated for this product.
  - Avoid direct water/liquid contact.
- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.
- Risk of Fire
  - Keep combustible materials away from lamp.

#### NOTES

- Lamp is made of heat resistant glass (HRG).