

Multipolar Protection  
Circuit protection  
breakers

**C60L circuit-breaker**

B, C, K and Z curves


IEC 60947-2: 25 kA ( $\leq 25$  A),  
20 kA (32-40 A), 15 kA (50-63 A)




25399



 
25426



25439

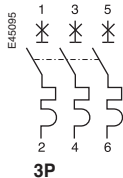

25452

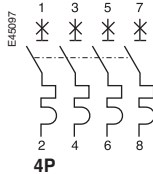

Catalogue numbers

Type	Rating (A)	Width in mod.	Catalogue number			
			B curve	C curve	K curve	Z curve
1P	0.5	2	-	25406	-	-
	1	2	-	25392	25460	26133
	2	2	-	25393	25462	26135
	3	2	-	25394	25463	26136
	4	2	-	25395	25464	26137
	6	2	25331	25396	25465	26139
	10	2	25332	25397	25467	26141
	16	2	25333	25398	25468	26142
	20	2	25334	25399	25469	26143
	25	2	25335	25400	25470	26145
	32	2	25336	25401	25471	26146
	40	2	25337	25402	25472	26147
	50	2	25338	25403	25473	-
	63	2	25339	25404	25474	-
2P	0.5	4	-	25407	-	-
	1	4	-	25418	25478	-
	2	4	-	25419	25480	26155
	3	4	-	25420	25481	26157
	4	4	-	25421	25482	26158
	6	4	25357	25422	25483	26159
	10	4	25358	25423	25485	26161
	16	4	25359	25424	25486	26163
	20	4	25360	25425	25487	26164
	25	4	25361	25426	25488	26165
	32	4	25362	25427	25489	26166
	40	4	25363	25428	25490	26167
	50	4	25364	25429	25491	-
	63	4	25365	25430	25492	-
3P	0.5	6	-	25408	-	-
	1	6	-	25431	25496	-
	2	6	-	25432	25498	26176
	3	6	-	25433	25499	26177
	4	6	-	25434	25500	26178
	6	6	25370	25435	25501	26180
	10	6	25371	25436	25503	26182
	16	6	25372	25437	25504	26184
	20	6	25373	25438	25505	26185
	25	6	25374	25439	25506	26224
	32	6	25375	25440	25507	26225
	40	6	25376	25441	25508	26226
	50	6	25377	25442	25509	-
	63	6	25378	25443	25510	-
4P	0.5	8	-	25409	-	-
	1	8	-	25444	25514	-
	2	8	-	25445	25516	26234
	3	8	-	25446	25517	26236
	4	8	-	25447	25518	26237
	6	8	25383	25448	25519	26239
	10	8	25384	25449	25521	26241
	16	8	25385	25450	25522	26242
	20	8	25386	25451	25523	26243
	25	8	25387	25452	25524	26244
	32	8	25388	25453	25525	26245
	40	8	25389	25454	25526	26246
	50	8	25390	25455	25527	-
	63	8	25391	25456	25528	-