


# XSDA600519

inductive sensor XSD 80x80x40 - plastic -  
Sn60mm - 24..240VAC - terminals



Product availability: Stock - Normally stocked in distribution facility

Price\*: 202.86 USD

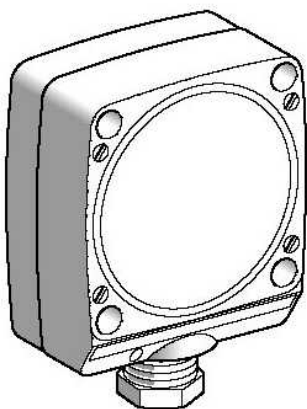

## Main

Commercial Status	Commercialised
Range of product	OsiSense XS
Series name	General purpose
Sensor type	Inductive proximity sensor
Product specific application	-
Sensor name	XSD
Sensor design	Form 80 x 80 x 40
Size	40 mm
Body type	Fixed
Enclosure material	Plastic
Type of output signal	Discrete
Wiring technique	2-wire
[Sn] nominal sensing distance	2.36 in (60 mm)
Discrete output function	1 NO or 1 NC programmable
Electrical connection	Screw-clamp terminals
[Us] rated supply voltage	24...240 V AC
IP degree of protection	IP67

## Complementary

Detection face	5 positions turret head
Detector flush mounting acceptance	Non flush mountable
Material	Plastic
Front material	Plastic
Output circuit type	AC
Cable entry	1 entry tapped for Pg 13.5 cable gland
Switching frequency	<= 10 Hz
Depth	1.57 in (40 mm)
Height	3.94 in (100 mm)
Width	3.15 in (80 mm)
Product weight	1.06 lb(US) (0.48 kg)

## Environment

Product certifications	CCC
Ambient air temperature for operation	-13...158 °F (-25...70 °C)

The information provided in this documentation contains general descriptions and/or technical characteristics of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein. \*Prices are indicative

## Ordering and shipping details

Category	22486 - SENSORS, PROXIMITY
Discount Schedule	DS2
GTIN	00785901232247
Nbr. of units in pkg.	1
Package weight(Lbs)	1.11
Product availability	Stock - Normally stocked in distribution facility
Returnability	Y
Country of origin	FR

## Offer Sustainability

Sustainable offer status	Green Premium product
RoHS	Compliant - since 1136 - <a href="#">Schneider Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available <a href="#">Download Product Environmental</a>
Product end of life instructions	Available <a href="#">Download End Of Life Manual</a>

## Contractual warranty

Period	18 months
--------	-----------