

Product data sheet


Characteristics

9001KM32

light block - incandescent BA 9s - 12 V AC/DC

Product availability: Stock - Normally stocked in distribution facility

Price*: 86.00 USD

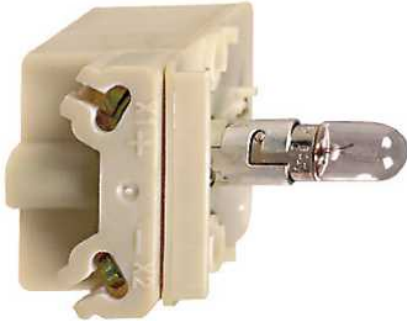

Main

Commercial Status	Commercialised
Range of product	Harmony 9001K Harmony 9001SK
Product or component type	Light block
Device short name	9001K
Bulb base	BA 9s
Light block supply	Direct via integral resistance

Complementary

Product weight	0.11 lb(US) (0.05 kg)
Light source	Incandescent
[Us] rated supply voltage	12 V AC/DC

Environment

Protective treatment	TC
Ambient air temperature for storage	-40...158 °F (-40...70 °C)
Ambient air temperature for operation	-13...158 °F (-25...70 °C)
IP degree of protection	IP20 conforming to IEC 60529
Standards	EN/IEC 60947-1 EN/IEC 60947-5-1 EN/IEC 60947-5-4 JIS C 4520 JIS C 852 UL 508 CSA C22.2 No 14
Product certifications	NEMA UL 508
Class of protection against electric shock	Class II
Vibration resistance	7 gn (f = 2...500 Hz) conforming to IEC 60068-2-6
Shock resistance	50 gn conforming to IEC 60068-2-27

Ordering and shipping details

Category	21435 - 9001 KM LIGHT MODULES
Discount Schedule	CS1
GTIN	00785901726418
Nbr. of units in pkg.	1
Package weight(Lbs)	0.14
Product availability	Stock - Normally stocked in distribution facility
Returnability	Y
Country of origin	MX

Offer Sustainability

Sustainable offer status	Not Green Premium product
RoHS	Compliant - since 0921 - Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold

Contractual warranty

Period	18 months
--------	-----------