

Table 9.105: Solid Neutral Lug Quantities and Sizes

Solid Neutral Assembly	Terminal Wire Range
HC2SN	(9)-#14-1/0, (1)-#6-300, (45)-#14-#4
HC4SN	(7)-#6 - 350, (45)-#14 - #4
HC6SN, HC6SNCU	(9)-#14 - 1/0, (7)-#6 - 350, (28)-#14 - #4
HC8SN	(9)-#14 - 1/0, (7)-#6 - 350, (34)-#14 - #4
HC8SNCU	(9)-#14 - 1/0, (7)-#6 - 350, (28)-#14 - #4
HCW12SN	(9)-#14 - 1/0, (7)-#6 - 350, (34)-#14 - #4, (4)-3/0-750
HCW12SNCU	(9)-#14 - 1/0, (7)-#6 - 350, (28)-#14 - #4, (4)-2/0-500
HCW4SN	(2)-#4-600, (7)-#6-350, (45)-#14-#4
HCW4SNCU	(9)-#14 - 1/0, (7)-#6 - 350, (28)-#14 - #4, (2)-#2-600
HCW6SN	(9)-#14 - 1/0, (7)-#6 - 350, (34)-#14 - #4, (4)-3/0-750
HCW6SNCU	(9)-#14 - 1/0, (7)-#6 - 350, (28)-#14 - #4, (2)-#2-600
HCW8SN	(9)-#14 - 1/0, (7)-#6 - 350, (34)-#14 - #4, (4)-3/0-750
HCW8SNCU	(9)-#14 - 1/0, (7)-#6 - 350, (28)-#14 - #4, (4)-3/0-750
HCWM12SN	(9)-#14 - 1/0, (7)-#6 - 350, (34)-#14 - #4, (4)-3/0-750
HCPSU8SN	(7)-#6-350, (34)-#4-#14, (9)-#14-1/0
HCPSU8SNCW	(3) 3/0-750, (7) #6-350, (34) #14-#4, (9) #14-1/0


Table 9.106: Panelboard Adapter Kits


Crimp Lug Adapter Kits [37]	I-Line Panelboard Type	
	HCM	HCP, HCR-U [38]
400 A	HCM400VCA	HCP400VCA
600 A	HCM600VCA	HCP600VCA
800 A	HCM800VCA	HCP800VCA
1200 A	—	HCP1200VCA

Table 9.107: Type 3R/5/12 Enclosures

Catalog Number	Interior Type	Dimensions (In.)		
		H	W	D
HC4250WP	HCP	50	42	12.95
HC4259WP	HCP	59	42	12.95
HC4268WP	HCP	68	42	12.95
HC4286WP	HCP	86	42	12.95
HC4486WP	HCR-U	86	44	14.50

Table 9.108: Box Extensions

	Catalog Number	Interior Type	Extension
	HC2609DEX (F or S)	HCP-SU	9 in.
	HC3209EX (F or S)	HCM	9 in.
	HC4212DEX (F or S)	HCP	12 in.
	HC4406DEX (F or S)	HCR-U	6 in.
	HC4412DEX (F or S)	HCR-U	12 in.

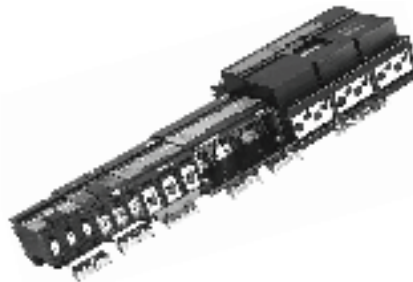

Sub-feed Lug Kits

[37] For use with MLO panel, order VCEL lugs separately.

[38] Not for use with P- or R-frame circuit breakers or sub-feed kits S33930 or S33931.