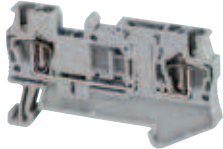
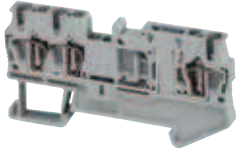
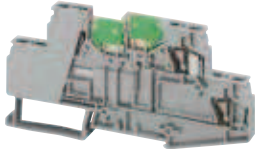



		Component carrier		Blade isolator			
							
		NSYTRR22TB	NSYTRR23TB	NSYTRR24SCD			
Nominal c.s.a.: mm ²		2.5	2.5	2.5			
Type of block		Component carrier	Component carrier	Blade isolator			
Type of connection		1 pole - 1 x 1	1 pole - 1 x 2	2 pole - 1 x 1			
Color		Grey	Grey	Grey			
Max. electric values (U _{max} , I _{max})		400 V, 20 A	400 V, 20 A	400 V, 16 A			
Approximate dimensions: mm (in.)							
Length		60.5 (2.38)	72 (2.84)	107 (4.21)			
Height		36.5 (1.44)	36.5 (1.44)	36.5 (1.44)			
Width		5.2 (0.21)	5.2 (0.21)	5.2 (0.21)			
Cabling c.s.a.: mm ²		2.5	2.5	2.5			
Flexible cable		0.08 - 2.5	0.08 - 2.5	0.08 - 2.5			
Solid cable		0.08 - 4	0.08 - 4	0.08 - 4			
Nominal electric values							
IEC/EN 60947-7-1		400 V, 20 A	400 V, 20 A	400 V, 16 A			
UL		300 V, 16 A, 28 - 12 AWG	300 V, 16 A, 28 - 12 AWG	300 V, 10 A, 28 - 12 AWG			
CSA		300 V, 16 A, 28 - 12 AWG	300 V, 16 A, 28 - 12 AWG	300 V, 10 A, 28 - 12 AWG			
ATEX 		-	-	-			
Certifications		UL File E87739 CNN XCFR2, CSA File 256444 Class 6228-01, GOST	UL File E87739 CNN XCFR2, CSA File 256444 Class 6228-01, GOST	UL File E87739 CNN XCFR2, CSA File 256444 Class 6228-01, GOST			
Terminal blocks							
		Sold in lots of	Catalog number	Sold in lots of	Catalog number	Sold in lots of	Catalog number
Grey		50	NSYTRR22TB	50	NSYTRR23TB	50	NSYTRR24SCD
Orange		-	-	-	-	-	-
Accessories							
End stop for 35 mm DIN rail	Clip-on, 5.2 mm	50	NSYTRAAB35	50	NSYTRAAB35	50	NSYTRAAB35
	With screw, 9.5 mm	50	NSYTRAABV35	50	NSYTRAABV35	50	NSYTRAABV35
End plate, width 2.2 mm	Grey	50	NSYTRACR23	50	NSYTRACR24	-	Included
	Blue	-	-	-	-	-	-
Partition plate, width 2 mm	Grey	50	NSYTRAPR23	50	NSYTRAPR24	-	-
	Blue	-	-	-	-	-	-
Plug-in jumper Red	2-pole	50	NSYTRAL22	50	NSYTRAL22	50	-
	3-pole	50	NSYTRAL23	50	NSYTRAL23	50	-
	4-pole	50	NSYTRAL24	50	NSYTRAL24	50	-
	5-pole	50	NSYTRAL25	50	NSYTRAL25	50	-
	10-pole	10	NSYTRAL210	10	NSYTRAL210	10	-
	20-pole	10	NSYTRAL220	10	NSYTRAL220	10	-
Removable carrier	For fuse 5 x 20 mm	10	NSYTRASF520	10	NSYTRASF520	-	-
	For fuse 5 x 20 mm 110 - 250 V LED	10	NSYTRASF520M	10	NSYTRASF520M	-	-
	For fuse 5 x 20 mm 12 - 30 V LED	10	NSYTRASF520B	10	NSYTRASF520B	-	-
	For component	10	NSYTRASV1	10	NSYTRASV1	-	-
	With 1N4007 diode	10	NSYTRASV2	10	NSYTRASV2	-	-
Test plug	Metallic part, Ø 2.3 mm	10	NSYTRAATM1	10	NSYTRAATM1	10	NSYTRAATM1
	Insulating sleeve, red	10	NSYTRAATP1	10	NSYTRAATP1	10	NSYTRAATP1
Test adapter	For plug-in jumper shaft	10	NSYTRAFT	10	NSYTRAFT	10	NSYTRAFT
Terminal cover	Yellow	50	NSYTRACSR2	50	NSYTRACSR2	50	NSYTRACSR2
Marker tag holder	For ●AB35 end stop	100	NSYTRASB4	100	NSYTRASB4	100	NSYTRASB4
DIN rail 35 x 7.2 mm	Perforated, 2 m long	20	NSYSDR200BD	20	NSYSDR200BD	20	NSYSDR200BD
Marking accessories		See page 74					
General data							
Strip length: mm (in.)		10 (0.39)		10 (0.39)		10 (0.39)	