


()

Communication Cards

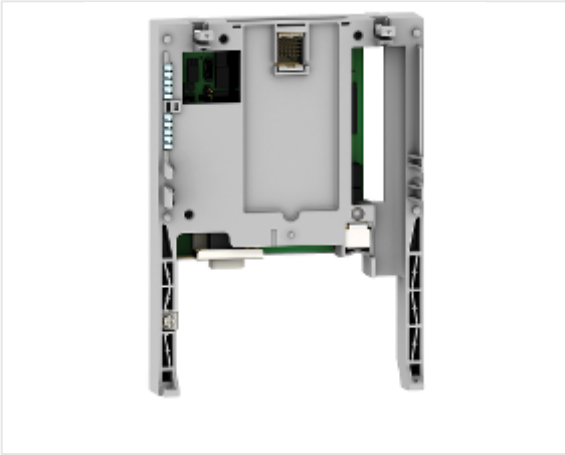

VW3A3316

Ethernet IP communication card - 10/100 Mbps - 2 RJ45

[Range: Altivar 61 Drive \(/en/product-range-selector/1422-altivar-61-drive\)](#)

[Documents & Downloads \(#drawer\)](#)

Price
275.1

(t
elec



[Product Datasheet \(/www.schneider-electric.us/en/product/download-pdf/VW3A3316/\)](http://www.schneider-electric.us/en/product/download-pdf/VW3A3316/)

[User guide \(http://download.schneider-electric.com/files?p_Reference=AAV68822&p_EnDocType=User guide&p_File_Id=687573215&p_File_Name=ATV61_71_EthernetIP_EN_AAV68822_03.pdf\)](http://download.schneider-electric.com/files?p_Reference=AAV68822&p_EnDocType=User%20guide&p_File_Id=687573215&p_File_Name=ATV61_71_EthernetIP_EN_AAV68822_03.pdf)

Characteristics

Main

product or component type	Communication card
range compatibility	Altivar 61 Altivar 71 Altivar 61Q Altivar 71Q
communication port protocol	Ethernet/IP
connector type	2 RJ45 connectors

transmission rate	10 Mbps 100 Mbps
--------------------------	---------------------

physical interface	IEEE 802.3
---------------------------	------------

web services	Drive monitor Drive parameters Drive recorder E-mail Ethernet/IP scanner setup Ethernet/IP setup Ethernet statistics Message statistics Security
---------------------	--

Ordering and shipping details

Category	22135 - ATV61-71 ACCESSORIES
-----------------	------------------------------

Nbr. of units in pkg.	1
------------------------------	---

Package weight(Lbs)	0.660000000000000003
----------------------------	----------------------

Returnability	Y
----------------------	---

Country of origin	ID
--------------------------	----

Contractual warranty

Warranty period	18 months
------------------------	-----------

Complementary

exchange mode	Half duplex and full duplex
----------------------	-----------------------------

communication data link	LLC : IEEE 802.2 MAC : IEEE 802.3
--------------------------------	--------------------------------------

communication network type	IP conforming to RFC791 ICMP
-----------------------------------	---------------------------------

communication transport type

TCP conforming to RFC793
UDP

web server

Embedded

communication service

BOOTP
CIP I/O data
I/O profile
CiA 402 profile
DHCP
Allen-Bradley drive profile
CIP AC Drive (02) profile

display type

1 LED TX/RX (Transmit/Receive port 1)
Graphic display terminal reference received
1 LED MS (Module Status)
1 LED NS (Network Status)
Graphic display terminal control word received
1 LED Link (Link Status)
1 LED TX/RX (Transmit/Receive port 2)

Documents and Downloads (2)

Recently Viewed Items



VW3A3316
Ethernet IP communication card
- 10/100 Mbps - 2 RJ45

(//www.schneider-electric.us/en/product/VW3A3316/ethernet-ip-communication-card---10-100-mbps---2-rj45/)



VW3A31201
control I/O card - for variable
speed drives Altivar 312

(//www.schneider-electric.us/en/product/VW3A31201/control-i-o-card---for-variable-speed-drives-altivar-312/)



TWDLCAE40DRF
compact PLC base Twido -
100..240 V AC supply - 24 I 24 V
DC - 16 O

(//www.schneider-electric.us/en/product/TWDLCAE40DRF/compact-plc-base-twido--100..240-v-ac-supply---24-i-24-v-dc---16-o/)