



## Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	General purpose

## Complementary

Electrical connection	Elbowed female connector, connector type: 1/2"20 UNF 3 pins
Cable connector fixing	Screw-on
Collar material	Metal
Status LED	Without
Cable length	2 m
Cable outer diameter	5.2 mm
Cable composition	3 x 0.34 mm <sup>2</sup>
Wire insulation material	PVC
[Ue] rated operational voltage	300 V DC 250 V AC
[In] rated current	4 A
Contact resistance	<= 5000 µOhm
Insulating resistance	>= 1 GΩ
Product weight	0.14 kg


## Environment

IP degree of protection	IP65 IP67
Ambient air temperature for operation	-25...80 °C (static)
Ambient air temperature for storage	-25...80 °C

## Offer Sustainability

Sustainable offer status	Not Green Premium product
RoHS (date code: YYWW)	Compliant - since 1201 - <a href="#">Schneider Electric declaration of conformity</a>

Dimensions

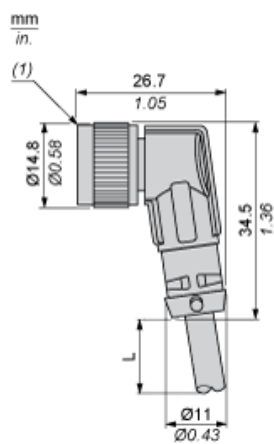


L : Length of cable  
(1) 1/2"-20UNF

---

## Connections and Schemes

---

### Connectors

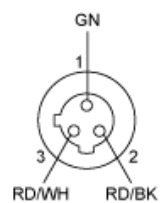

GN : Green  
RD/ Red / White  
WH :  
RD/ Red / Black  
BK :