



PAR20

PAR20E 20W 120V 10D 1CT

Philips Halogen PAR lamps will provide bright, white light across the product line and feature excellent beam qualities for accent or ambient lighting. Their optimized coil and burner design allows for clear, crisp lighting effects with excellent color rendering, making it easy to optimize the look and feel of your store and your merchandise.

Product data

• General Characteristics

Base	E27
Bulb	PAR20 [PAR 2.5 inch]
Operating Position	Universal [Any or Universal (U)]
RatedAvgLife(See Family Notes)	5000 hr

• Light Technical Characteristics

Beam Angle	10 D
Beam Angle Technical	8.5 D
Approx. MBCP	7000 (max) cd
Color Temperature	2880 K
Color Temperature technical	2880 K

• Electrical Characteristics

Watts	20 W
Lamp Wattage Technical	21.5 W

Voltage 120 V

• Product Dimensions


Overall Length C	85.9 (max) mm
Diameter D	63.5 (max) mm

• Product Data

Product number	404947
Full product name	PAR20E 20W 120V 10D 1CT
Short product name	20PAR20E/SP10 120V 12/1
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677404949
Bar code on case	50046677404944
Logistics code(s)	924780236301
tpd_ilcos_cd	HRGI-20-120-E27
eop_net_weight_pp	120.000 gr

Dimensional drawing

Dimensional drawing

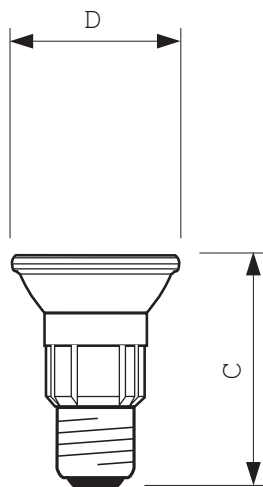

E27

E27, PAR20 E

Product	C (Max)	D (Max)
HPAR20 E 20W E27 120V PAR20 10D	85.9	63.5



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change