

LED Site/Roadway/Wall Pack Lamp Series



Stock No. **Product Description**
LED-8001-DL **PT-120/277-35W-35LED-DL (Daylight)**
LED-8001-NW **PT-120/277-35W-35LED-NW (Neutral White)**

Description:

Mogul base Hi Power 35W LED Site / Roadway or Wall Pack lamp that can replace a 75-100W MH/HPS light output in an energy saving, 50,000 hr. alternative to Metal Halide, HPS, Fluorescent, or Incandescent lighting. Available in Daylight DL (5700K) or Neutral White NW (3000K).

- 35 Watt
- 100-277 Volt operation
- Daylight DL (5700K) or Neutral White (3000K)
- Lumens: 2400(DL), 2300(NW)
- 35 on-board LED SMDs
- Up to 50,000 hour lamp life
- Minimal heat output
- Not dimmable
- 5 year warranty
- Active Cooling Delta 70K Hr Fan
- LM 79 Available
- UL damp location Listed

Applications:

LED Site/Roadway/Wall Pack Series lamps can impact energy usage and costs in a major way for communities and housing developments with minimal to no maintenance costs thanks to the up to 50,000 hour lamp life.


- Site/Roadway/Post Top
- Wall packs (where applicable)
- Security lighting
- Parks and quads
- Municipal lighting

Packaging:

Master pack: 6 each

Note: Maximum height from ground is 7 meters

Note: When retrofitting LED to HID fixture, ballast must be bypassed when present. Eliminating the ballast saves additional costs related to maintenance, energy consumption and performance. Additionally, by-passing ballast will insure no RFI interference.

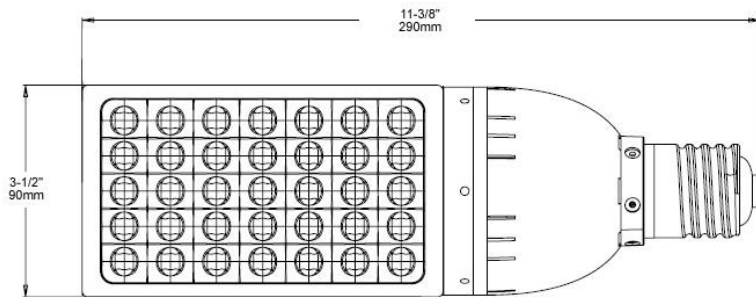

Technical Specifications:

Bulb Type:	Site/Roadway/Wall	Mounting:	Mogul E39
Bulb Material:	Alum/Polycarbon	Replaces:	75-100W MH/HPS
CRI:	85	Life Time:	Up to 50,000 Hrs.
Output Power:	35W	Input Voltage:	AC 100 – 277V
Lumens:	2400(DL), 2300(NW)	Beam Angle:	120 °
Dimensions:	3-1/2" x 11-3/8" 90mm x 290mm	Kelvin Temp:	(DL) 5700K (NW) 3000K
Lumen per Watt:	68-70	LEDs:	35 Hi Power LEDs

Note: All specification information falls within a ± 2% range and is subject to change without notice.

NOTE: Light Efficient Design is providing this information to the general public. Please note that all products contained herein are trademarked, copyrighted, and/or have patents pending. Any use of these designs is strictly prohibited without prior written consent. Light Efficient Design protects its proprietary information vigorously in the courts of the United States of America.

106 S. Wynstone Park Drive • N. Barrington, IL 60010
 (847) 380-3540 • FAX: (847) 380-3542
 www.led-llc.com

